

# Fastener for aluminium profile

PRF **MiniTec**

Universal fastener

FIXUNI





## Uses

- Low cost fastening requiring little preparation
- Used for different assembly types

## Central hole

- Directly accepts M8 screws

Quick-fixing

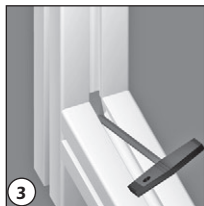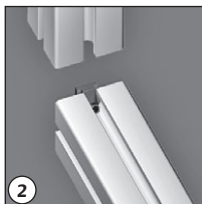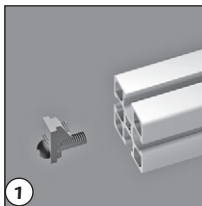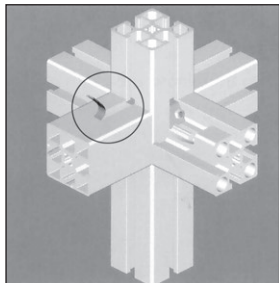

## Assembly

1. Tap the central hole of the first profile (1) using a fluteless M8 tap.  
Lightly attach the fastener to the end of the profile using the M8 screw (do not screw in completely)
2. Attach the second profile (2) in the required position.
3. Tighten the M8 grub screw with an SW4 hexagonal key or the PRF-TOOL-H4 tool.  
Max. Suggested torque 12Nm

## Advantages



- Ends of profiles remain available
- Fastener is not visible
- Profiles can be repositioned/adjusted at any time
- Assembly will not twist
- Maximum load allowed: 6000N
- Cross joints in 3 dimensions can be created
- Joint can conduct electricity for bonding purposes.

**Profile assembly**

- Can be used to join all profile types
- Use multiple fasteners for longer lengths
- Materials:
- Fastener: electroplated chromed steel or stainless steel
- Round headed M8 screw, 25mm long.

**Assembly**

- Lightly attach the fastener into the slot on the profile (do not tighten)
- Slide the fastener in the slot to the required position
- Tighten the M8 grubscrew with an SW4 hexagonal key or the **PRF-TOOL-H4** tool

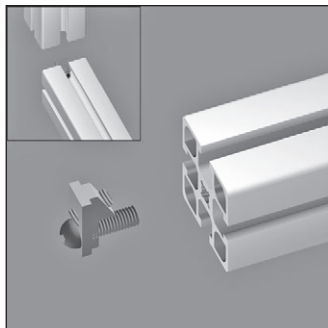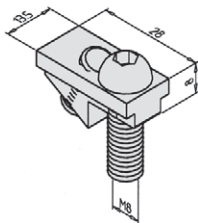**No drilling****DISCOUNTS**

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	For profile	Tightening torque (Nm)	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-UNI	All type of PRF profile	10,0	0,029	✓	5,18 €
PRF-FIX-UNI/SS	Stainless PRF/SS profile	01,2	-	✓	11,40 €

\*Depending on availability - Dimensions in mm


## Altri prodotti...



STRIPF  
Spazzola strip,  
Lunghezza 1m



DEP  
Attrezzi Hygienic  
Usit® and Hygienic  
Design®, Bussole per  
il monta...

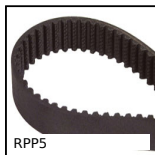

RPP5  
Cinghia di  
trasmissione RPP,  
RPP5



NCT  
Giunto di  
collegamento, Ad  
angolo fisso



ZDB  
Ingranaggio conico in  
plastica, 2:1



PRS50  
Piede snodato tutto  
inox Ø50, Ø 50



RFV63  
Riduttore inox a ruota  
e vite senza fine, fino  
a 152 Nm



PTGP  
Puleggia folle, Per  
cinghia piatta



FBL6000\_K13  
Spazzola al metro,  
Polipropilene nero



BCA  
Ghiera scanalata  
cilindrica in acciaio,



BOX-CS  
Fascette di serraggio,  
Valigetta di fascette



PM4  
Coppia ruota e vite  
senza fine, Bronzo

## Prodotti correlati



PRF1932  
Profilato alluminio  
standard, 19 x 32 mm



PRF4545  
Profilato inox  
standard, 45 x 45 mm



PRF\_FIX\_STD  
Fissaggio, Fissaggio  
standard



PRF\_FIX\_ANG  
Fissaggio, Fissaggio  
angolare