

# Fastener for aluminium profile

PRF **MiniTec**

Universal fastener

FIXUNI



## Uses

- Low cost fastening requiring little preparation
- Used for different assembly types

## Central hole

- Directly accepts M8 screws

Quick-fixing

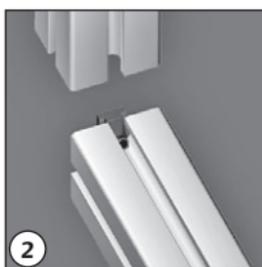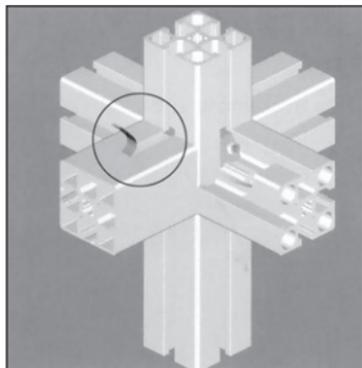

## Assembly

1. Tap the central hole of the first profile (1) using a fluteless M8 tap.  
Lightly attach the fastener to the end of the profile using the M8 screw (do not screw in completely)
2. Attach the second profile (2) in the required position.
3. Tighten the M8 grub screw with an SW4 hexagonal key or the PRF-TOOL-H4 tool.  
Max. Suggested torque 12Nm

## Advantages


- Ends of profiles remain available
- Fastener is not visible
- Profiles can be repositioned/adjusted at any time
- Assembly will not twist
- Maximum load allowed: 6000N
- Cross joints in 3 dimensions can be created
- Joint can conduct electricity for bonding purposes.

### Profile assembly


- Can be used to join all profile types
- Use multiple fasteners for longer lengths
- Materials:
- Fastener: electroplated chromed steel or stainless steel
- Round headed M8 screw, 25mm long.

### Assembly

- Lightly attach the fastener into the slot on the profile (do not tighten)
- Slide the fastener in the slot to the required position
- Tighten the M8 grubscrew with an SW4 hexagonal key or the **PRF-TOOL-H4** tool

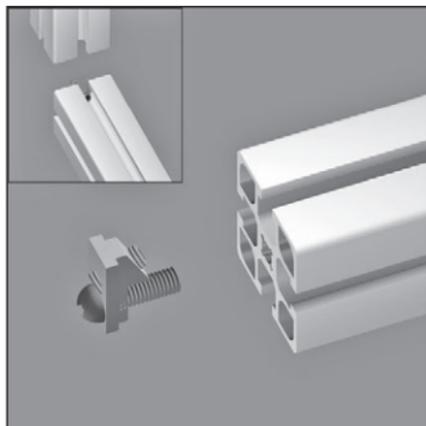

**No drilling**

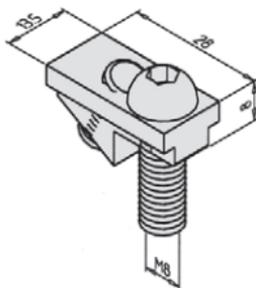

### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Tightening torque (Nm)	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-UNI	All type of PRF profile	10,0	0,029	✓	5,18 €
PRF-FIX-UNI/SS	Stainless PRF/SS profile	01,2	-	✓	11,40 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



VTSM

Ball head screws  
Hygienic Design®,  
Inox



PTA80ssEB

Piede snodato con  
base stampata Ø80,  
10000N



F7-P-AM

Visualizzatore  
multifunzione, Anello  
magnetico



BLH30

Rinvio angolare a L,  
da 1.32 a 4.40 Nm



WW16

Carrello Drylin® W,  
Carrello



PGR

Impugnatura cilindrica  
libera retraibile,  
Retraibile



PT821

Pignone di trazione,  
Serie 821 e 805



PAV

Piede fisso,  
Antivibrante



RFK58C

Riduttore ipoide inox,  
fino a 500 Nm



STRIPF

Spazzola strip,  
Lunghezza 1m



PRF\_GAL

Rotella per profilo  
alluminio, Rotella  
liscia



MSP23

Inserto con piastrina a  
incollare  
Masterplate®,  
Cilindrico Ø23 con...

## Prodotti correlati



PRF1932

Profilato alluminio  
standard, 19 x 32 mm



PRF4545

Profilato inox  
standard, 45 x 45 mm



PRF\_FIX\_STD

Fissaggio, Fissaggio  
standard



PRF\_FIX\_ANG

Fissaggio, Fissaggio  
angolare