

Fastener for aluminium profile

PRF **MiniTec**

Universal fastener

FIXUNI





Uses

- Low cost fastening requiring little preparation
- Used for different assembly types

Central hole

- Directly accepts M8 screws

Quick-fixing

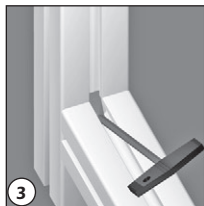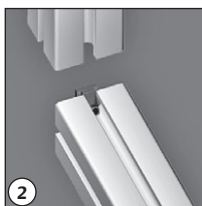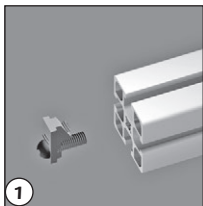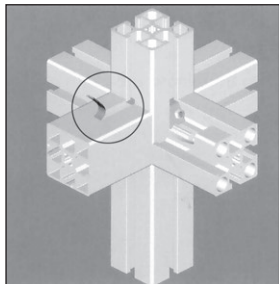

Assembly

1. Tap the central hole of the first profile (1) using a fluteless M8 tap.
Lightly attach the fastener to the end of the profile using the M8 screw (do not screw in completely)
2. Attach the second profile (2) in the required position.
3. Tighten the M8 grub screw with an SW4 hexagonal key or the PRF-TOOL-H4 tool.
Max. Suggested torque 12Nm

Advantages



- Ends of profiles remain available
- Fastener is not visible
- Profiles can be repositioned/adjusted at any time
- Assembly will not twist
- Maximum load allowed: 6000N
- Cross joints in 3 dimensions can be created
- Joint can conduct electricity for bonding purposes.

Profile assembly

- Can be used to join all profile types
- Use multiple fasteners for longer lengths
- Materials:
- Fastener: electroplated chromed steel or stainless steel
- Round headed M8 screw, 25mm long.

Assembly

- Lightly attach the fastener into the slot on the profile (do not tighten)
- Slide the fastener in the slot to the required position
- Tighten the M8 grubscrew with an SW4 hexagonal key or the **PRF-TOOL-H4** tool

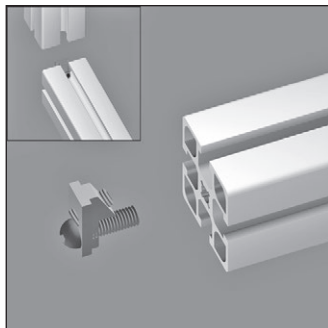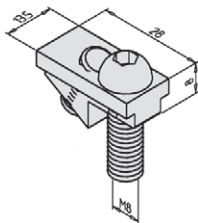**No drilling****DISCOUNTS**

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	For profile	Tightening torque (Nm)	Weight (kg)	Stock*	Price each 1 to 49
PRF-FIX-UNI	All type of PRF profile	10,0	0,029	✓	5,18 €
PRF-FIX-UNI/SS	Stainless PRF/SS profile	01,2	-	✓	11,40 €

*Depending on availability - Dimensions in mm


Altri prodotti...



BABpss
Perno autobloccante,
Inox



M0
Vite senza fine ,
Acciaio non temprato

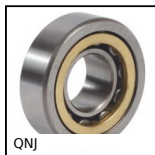

QNJ
Cuscinetto a singola
corona di rulli
cilindrici, Anello
interno fiss...



PSG125
Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



M0
Coppia ruota e vite
senza fine , Acciaio
non temprato



GAC
Chiusura a leva con
serratura, Riscontro
grezzo



CHAC4040NP
Cerniera, Quadrata
con rivetto senza fori



PV1R
Braccio portaventosa
orientabile, Serraggio
standard




GGB
Dado ad alette, Cieco



KB_UU
Manicotto a sfere di
precisione, Di
precisione - acciaio



J51
Riduttore coassiale a
treni paralleli, da 0.13
a 0.49 - a treni para...

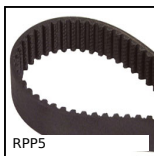

RPP5
Cinghia di
trasmissione RPP,
RPP5

Prodotti correlati



PRF1932
Profilato alluminio
standard, 19 x 32 mm



PRF4545
Profilato inox
standard, 45 x 45 mm



PRF_FIX_STD
Fissaggio, Fissaggio
standard



PRF_FIX_ANG
Fissaggio, Fissaggio
angolare