

Lip seal for panel

PRFJL **MiniTec** For 2mm thick panels

- Material: black EPDM
- Seal sold by the metre

Uses



- For supporting and sealing 2mm thick panels in profile slots
- Should not be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool
- For panels thinner than 2mm, use 2 PRF-JL-6 seals on either side of the panel instead.

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

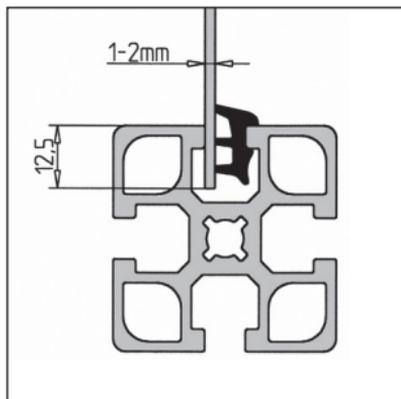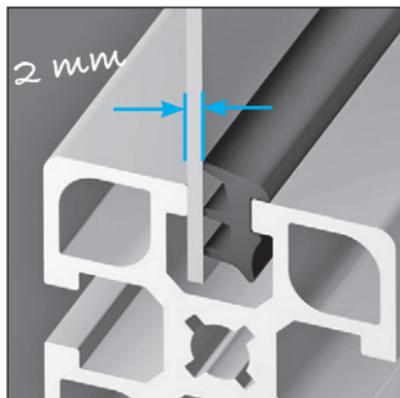

Assembly example

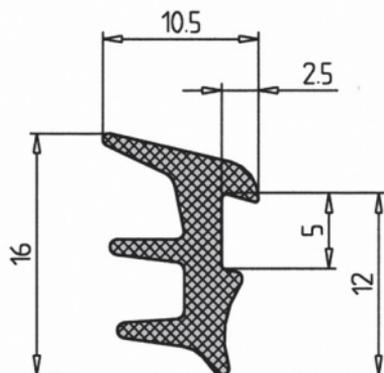

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-2	Lip seal	0,092	3,17 €

Dimensions in mm

Altri prodotti...



HTD8M_50

Puleggia dentata di trasmissione tipo HTD, HTD8 Acciaio



PSG1

Ingranaggio dritto di precisione, Acciaio 35NCD6 pretrattato



MSP38

Inserto con piastrina a incollare Masterplate®, Cilindrico Ø38 con...



RT25ss

Self-centering flanged locking assembly, Coppia media/elevata



NPTR

Morsetto, Regolabile



UGH20

Unità di guida tipo H, Per martinetti Ø20



ZDB

Ingranaggio conico in plastica, 2:1



SCH

Attrezzo di bloccaggio a tirante, A tirante orizzontale - acciaio



BAG0

Anello di bloccaggio, Acciaio



JFM

Cuscinetto a collare, Polimero universale



HLUT

Volantino con razze e impugnatura girevole, Alluminio



P70

Riduttore a ruota e vite senza fine, fino a 164 Nm

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm