

Lip seal for panel

For 4mm thick panels

MiniTecPRFJL

- Material: black EPDM AGV
- Seal sold by the metre

Uses



- For supporting and sealing 2-4mm thick panels in profile slots
- Can be used with acrylic or polycarbonate panels

Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

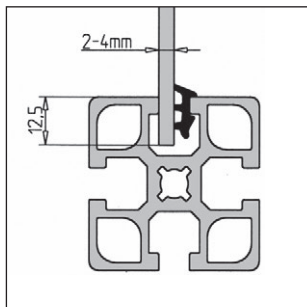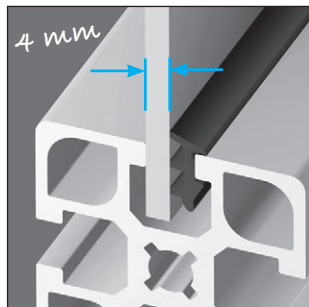

Assembly example

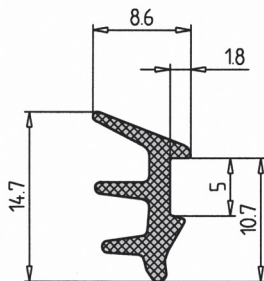

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-4	Lip seal	0,065	2,17 €

Dimensions in mm

Altri prodotti...



SHW
Rondella semplice ,
Inox A2



BOX-TOR-G
Valigetta di
guarnizioni toriche in
nitrile, 3.00 x 1.50mm
a 30.20 x...



G4
Ingranaggio dritto
acciaio , Acciaio
20NCD2



ACLBTS
Sistema di chiusura,
Blocca porta a sfera



BDP1R
Braccio di reazione,
Serraggio standard



D19_D29
Molla di compressione
al metro acciaio, al
metro




SHTP
Tavola lineare
Drylin®, Economica



BMM
Manopola, zigrinata



BOXdhx
Box kit di spine
filettate DIN7979D,
Box kit - estraibile DIN

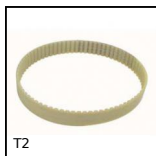

T2
Cinghia di
posizionamento T,
T2.5 Poliuretano



CLG3
Ingranaggio dritto in
plastica stampata ,
Nylon stampato



ACM_AZ
Aggancio per tirante
chiusura in gomma,
Aggancio

Prodotti correlati



PRF4545
Profilato alluminio
standard, 45 x 45 mm