

# Lip seal for panel

For 6mm thick panels

**MiniTec**PRFJL

- Material: black EPDM AGV
- Seal sold by the metre

## Uses



- For supporting and sealing 6mm thick panels in profile slots
- Can be used with plexiglass or polycarbonate panels
- Can also be used to support panels thinner than 2mm by using a seal on each side

## Assembly


- Place the panel in the profile slot
- Insert the lip seal
- Press seal into place with suitable blunt tool

## Info.

- Max length available 200m
- Panels: Add 25mm to height and width of aperture to ensure panel will be supported correctly

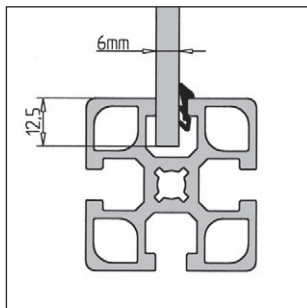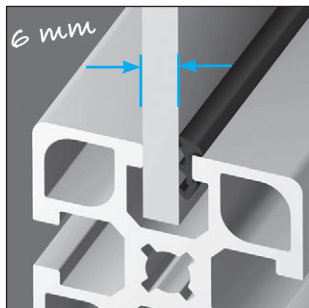

Assembly example

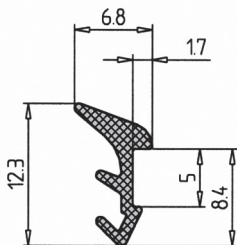

## DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg/m)	Price per metre
PRF-JL-6	Lip seal	0,033	1,58 €

Dimensions in mm

## Altri prodotti...



PSG125S

Ingranaggio dritto di precisione, Inox 316



M1

Vite senza fine ,  
Acciaio non temprato



AFSE

Perno di fissaggio, con  
chiusura a scatto



AT5M AT10M

Cinghia aperta al  
metro tipo AT, AT10  
Poliuretano armatura  
in acciaio



BPHRF

Sfera portante, Forte



HRV

Sistema di guida su  
binario a V Simple  
Select®, Binario con  
carrello



EPRC

Dado cilindrico a  
passo lungo, Dado  
cilindrico-fino a 40mm  
di corsa ...



SH1

Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



RHTtcss

Ruota alte  
temperature, fino a  
200kg



GB-RA

Ingranaggio dritto  
ottone, Ottone  
CuZn39Pb3



BTESS

Tenditore automatico  
universale per  
tenditore, Per



LVT

Mini martinetto  
motorizzato 4A, 4  
ampere

## Prodotti correlati



PRF4545

Profilato alluminio  
standard, 45 x 45 mm