




- Supplied with profile fixing kit
- Material: grey powder covered steel

### Uses


- For attaching panels or chassis to floors
- Suitable for all profiles up to 45x45mm

### Assembly

- Insert the profile into the foot
- Insert nuts with sprung tabs into the slots on the profile and lightly tighten the screws
- Make final adjustments to the position of the profile and then firmly tighten the screws
- Use anchoring system if fixing to a floor

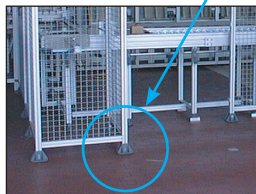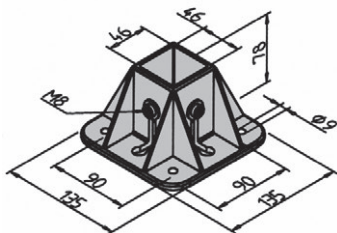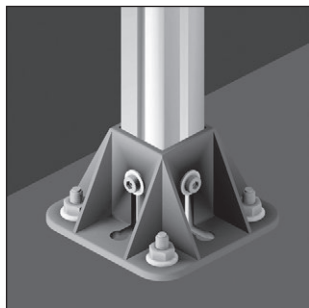

Typical application

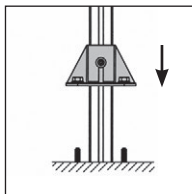

Mounting example


### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-P-45	Anchor	0,595	✓	18,81 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...

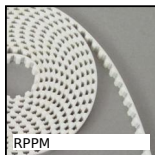

RPPM

Cinghia aperta al metro tipo RPP, RPP8 Poliuretano armatura in acciaio



CLM

Attacco per forcella, Corta acciaio



BAG

Anello di bloccaggio in acciaio, Acciaio



KB\_UU

Manicotto a sfere di precisione, Di precisione - acciaio



SBS\_L

Giunzione per catena al metro, Falsa maglia - inox



PRF\_BV

Blocchetto di fissaggio, Aggiunta e fissaggio di pannelli



PNA

Giunto elastico PERIFLEX®, Giunto completo



CFES

Perno folle eccentrico, Eccentrico



LVT

Mini martinetto motorizzato 2A, 2 ampere



CHM40

Riduttore a ruota e vite senza fine, fino a 57 Nm



PPG

Pistoncino a molla, Con flangia di fissaggio orizzontale



GGP

Vite ad alette, Tecnopolimero con inserto in acciaio

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm