

# Internal hinge pin for aluminium profile

## MiniTecPRFPIV

- Supplied with fixing kit
- Material: anodised aluminium

### Uses



- Doors
- Panels
- Sections of structures that need to move

### Assembly

- Slide the pin to the required location in the slot of the upper support profile and tighten.
- Repeat for lower profile.
- Add the spacers
- Insert the other part of the pin into the central hole at the top of the door profile, repeat for bottom of door
- Assemble the door into the frame ensuring the two parts of each hinge are in the correct position. Tighten the 2 grub screws on each hinge

### Info.

- Max. load: 250N

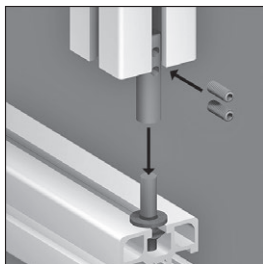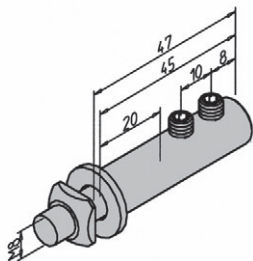

Typical application



### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
PRF-PIV	Hinge pin	0,02	✓	7,70 €


\*Depending on availability - Dimensions in mm

## Altri prodotti...



RJA11\_27

Guarnizione in gomma, Diverso dall'aggancio

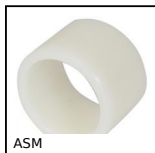

ASM

Cuscinetto cilindrico, Polimero alimentare



AT5courroie

Cinghia chiusa posizionamento AT, AT5 Poliuretano armatura in acciaio



CHAL55

Cerniera piana inox, Inox



ACM\_AZ

Aggancio per tirante chiusura in gomma, Aggancio



GE32

Chiusura a leva rigida ad anello, Standard



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



BAC105

Contenitore a becco, 8mm



PML

Piede massiccio per carichi pesanti, Ø 100,



NKXR

Cuscinetto combinato senza anello interno,



CABPVC

Cavo acciaio galvanizzato con PVC



BPLF

Sfera portante alta sporgenza, Leggero

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF\_ART

Cerniere e giunti, Con maniglia di serraggio