

Shaft support for aluminium profile Stock

PRFPSA **MiniTec** For attaching a guidance shaft to a profile Z12

- Support profile for linear guide shafts

- Materials:

Profile: anodised aluminium E6/V1

Steel shaft: Cf53 hardened (62 +/-2 HRC) Stainless steel

shaft: hardened stainless steel X90CrMoV18 (57 +/-2 HRC)

Shaft end stop: grey power coated aluminium

(Fixing kit supplied)




Assembly


- Insert the shaft support profile into the profile slot
- Secure with M5x10 grub screws
- Insert the shaft into the support profile with the aid of a plastic mallet if necessary

Accessories

- Roller PRF-GAL-12
- Shaft end stop PRF-12-AA

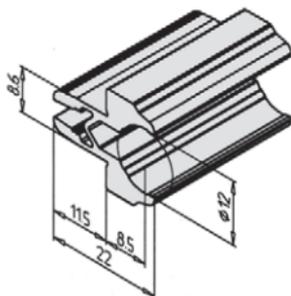

PRF-12-PSA

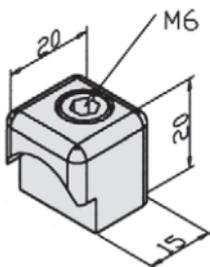

PRF-12-AA

DISCOUNTS

| | | | |
|-------|----------|------------|------|
| Qty. | 1+ | 50+ | 100+ |
| Disc. | List -5% | On request | |

DISCOUNTS SHAFTS Z

| | | | | | | |
|-------|-----------|-----------|-----------|-----------|------------|------|
| Qty. | 1+ | 6+ | 20+ | 40+ | 60+ | 100+ |
| Disc. | List -10% | List -15% | List -20% | List -25% | On request | |

| Part number | For profile | Material | Length | Weight (kg/m) | Stock* | Price each |
|------------------------------|-------------|-----------------|--------|---------------|--------|------------|
| Shaft support profile | | | | | | |
| PRF-12-PSA | all types | - | 3000 | 0,36 | ✓ | 22,85 € |
| Linear guidance shaft | | | | | | |
| Z-12-3000A | | steel | 3000 | 0,89 | - | 46,08 € |
| Z-12-3000B | | stainless steel | 3000 | 0,89 | - | 148,34 € |
| Shaft end stop | | | | | | |
| PRF-12-AA | | - | - | 0,03 | - | 6,20 € |

*Depending on availability - Dimensions in mm

Altri prodotti...



GE_ES

Snodo sferico,
acciaio/acciaio



RTL450

Calettatore di
bloccaggio, Coppia
elevata




PX_PO

Maniglia -
movimentazione
manuale, standard



P60

Riduttore a ruota e
vite senza fine, fino a
118 Nm

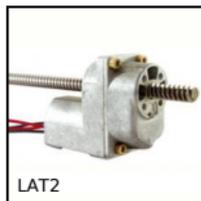

LAT2

Attuatore lineare a
motore 2A, 2 ampere



CHA1056_U4

Cerniera ad avvitare,
Sezione 40X40



PLM-SC

Magnete piatto, With
threaded hole



DOG316

Motoriduttore DC 12V
e 24V DC, da 1.5 a 2
Nm



CHAu

Cerniera ad avvitare,
270°




MLY

Grillo con chiodo ad
occhiello, Acciaio



SSDB

Ingranaggio conico
inox, 2:1

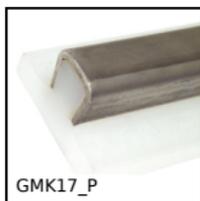

GMK17_P


Guida prodotto
laterale piatta, Per
imbottigliamento e
imballaggio

Prodotti correlati



PRF_GAL

Rotella per profilo
alluminio, Rotella
cava $\varnothing 12$

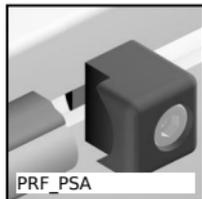

PRF_PSA

Rotella per profilo
alluminio, per
bloccaggio albero