

Caster for use with aluminium profile

Without brake

MiniTecPRFROUL

- Supplied with fixing kit
- Materials:
 - Casing : black polyamide
 - Double wheel: black polyamide
- Max. load: 30kg

Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

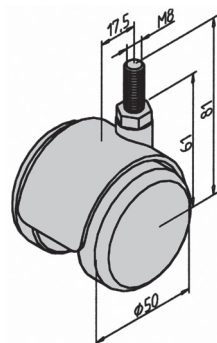

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Price each 1 à 49
PRF-ROUL	Caster without brake	0,076	7,89 €

*Depending on availability

Altri prodotti...



BABFCFO

Perno autobloccante,
Boccole di fissaggio
con flangia cilindrica




PLM-20SC

Magnete cilindrico,
Magnete cilindrico



PRF_BV

Blocchetto di
fissaggio, Aggiunta e
fissaggio di pannelli

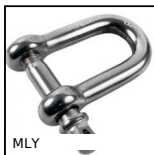

MLY

Grillo con chiodo ad
occhiello, Acciaio



SBS_L

Giunzione per catena
al metro, Falsa maglia
- inox



PRF_CHA D

Cerniera ad avvitare,
Scardinabile



SH3

Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



BAG0

Anello di bloccaggio,
Inox




RFK58C

Riduttore ipoide inox,
fino a 500 Nm



PRF-P

Supporto piede, Per
piedi o ruote

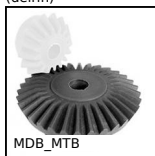

MDB_MTB

Ingranaggio conico in
plastica stampata ,



SF_ZZ

Cuscinetto radiale a
sfere, Inox

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm