

Caster for use with aluminium profile

Without brake

MiniTecPRFROUL

- Supplied with fixing kit
- Materials:
 - Casing : black polyamide
 - Double wheel: black polyamide
- Max. load: 30kg

Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

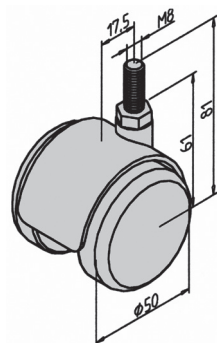

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (kg)	Price each 1 à 49
PRF-ROUL	Caster without brake	0,076	7,89 €

*Depending on availability

Altri prodotti...



BDPR
Braccio di reazione,
Rigido



BCFH
Pomello a fungo
Hygienic Usit®, Con
perno filettato e
collare alto



STRIPF
Spazzola strip,
Lunghezza 1m



BL8
Rinvio angolare, da
0.20 a 2 Nm



SSHBRA
Ingranaggio conico
inox, 1,5:1 2:1 3:1



DOMI80
Slitta di regolazione
Domino 80, Slitta
DOMILINE 80 con
contatore e ...



SH2
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



SBF
Sealed flange bearing
unit for Food Industry,
cover



RAM30
Riduttore manuale,
Rinvio angolare



ACL-FPA
Accessori per pannelli,
Morsetto di fissaggio



CHAR
Cerniera a molla,
avvitabile



ACLEPP
Angolare, 4 fori

Prodotti correlati



PRF4545
Profilato alluminio
standard, 45 x 45 mm