

Caster for use with aluminium profile

PRFROUL **MiniTec**

With brake

- Supplied with fixing kit
- Materials:
 - Casing : black polyamide
 - Double wheel: black polyamide
- Max. load: 30kg

Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

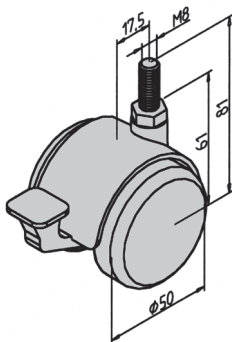

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Price each 1 à 49
PRF-ROUL/F	Caster with brake	0,08	9,71 €

*Depending on availability

Altri prodotti...



NPTF20

Morsetto di collegamento,
Distanziale Ø10 a Ø14



PSG05HC

Ingran. dritto di
precisione trattato
skiving, Acciaio
20NCD2 cement...



DB

Ingranaggio conico in
acciaio, 2:1



RFVcap

Coperchio di
protezione inox,
Coperchio di
protezione aperto



DER63

Motore inox AC
asincrono 0,18kW,
0.18kW



DOMI50

Accessori di
collegamento, Kit di
fissaggio



SVT15

Martinetto a vite - Vite
traslante, Vite
traslante



LVT

Mini martinetto
motorizzato 1A, 1
ampere



PW_PWG05

Vite senza fine di
precisione, Acciaio



RTTss

Calettatore di
bloccaggio, Coppia
media/elevata



CFF

Testa a snodo
femmina DIN
ISO12240-4, Acciaio /



ZG125

Ingranaggio dritto in
plastica, Plastica
lavorata (delrin)

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm