

Caster for use with aluminium profile

PRFROUL **MiniTec**

With brake

- Supplied with fixing kit
- Materials:
 - Casing : black polyamide
 - Double wheel: black polyamide
- Max. load: 30kg

Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

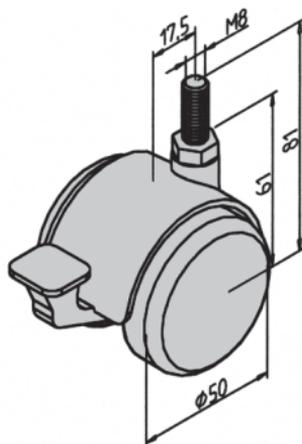

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Price each 1 à 49
PRF-ROUL/F	Caster with brake	0,08	9,71 €

*Depending on availability

Altri prodotti...



AC144

Piastrina di riscontro
piatta per chiusura,
22mm



DER63

Motore inox AC
asincrono 0,18kW,
0.18kW



CTZYSS

Antivibrante elastico
inox sgolato, Inox



HK

Accessorio di
serraggio manuale,
Serraggio manuale
LWL



SC2

Giunto rigido in 2
parti, Ganascia di
serraggio



BSCf

Manopola, Con coppia
regolabile



GDR880

Guida dritta, Serie
880 e 881



VTHbr

Vite a testa esagonale
- DIN933, Ottone



BABPass

Perno autobloccante
inox temprato ad
anello, Con



SVT30

Martinetto a vite - Vite
traslante, Vite
traslante



KBS_UU

Manicotto chiuso a
sfere inox di
precisione, Di



MFBS

Giunto a soffietto
Inox, Inox - con vite a
pressione

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm