

# Caster for use with aluminium profile

## PRFROUL **MiniTec**

### With brake

- Supplied with fixing kit
- Materials:
  - Casing : black polyamide
  - Double wheel: black polyamide
- Max. load: 30kg

#### Uses


- Light mobile tables
- Wheeled filing cabinets
- Furniture

#### Assembly

- Tap (M8) the central hole of the profile and screw on the caster



Typical application

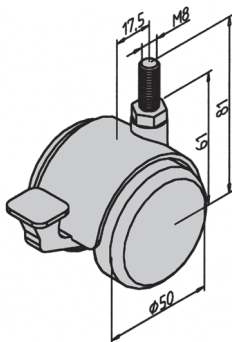

#### DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Type	Weight (kg)	Price each 1 à 49
PRF-ROUL/F	Caster with brake	0,08	9,71 €

\*Depending on availability

## Altri prodotti...



BFDdII  
Boccola di fermo per perno ad innesto, Acciaio nichelato



PLS  
Distanziatore cilindrico, Inox 303



ACM\_TRI  
Tirante chiusura in gomma, Caucciù



BSPM  
Vite a ricircolo di sfere miniatura, Dado + vite a ricircolo di sfere



GCL  
Guida lineare a sfere Eco, economica



G0  
Ingranaggio dritto acciaio, Acciaio 20NCD2



LACM\_SS  
Leva a camma inox, Femmina



CDGamme  
Molla di compressione DIN2095, DIN 2095



SLBW  
Pistoncino a molla, Da saldare - Acciaio



CHA  
Cerniera, Robusta - Apertura 180°



HTD14M\_85  
Puleggia dentata di trasmissione tipo HTD, HTD14 Acciaio



PTA100ssEB  
Piede snodato con base stampata Ø100, Piede snodato

## Prodotti correlati



PRF4545  
Profilato alluminio standard, 45 x 45 mm