
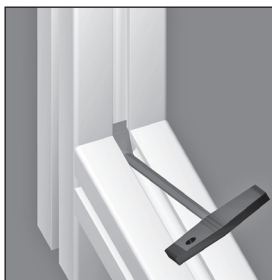


Assembly key

- Materials:
Shaft: chromed steel
Handle: black plastic

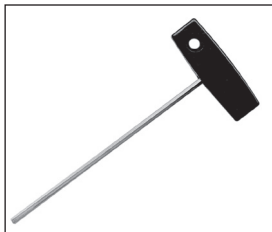

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%		On request

Part number	Type	SW	Weight (kg)	Stock*	Price each 1 to 4
PRF-TOOL-H4	Clef de montage	4	-	✓	13,47 €
PRF-TOOL-H5	Clef de montage	5	-	✓	13,82 €

*Depending on availability - Dimensions in mm

Altri prodotti...



DOMI30

Kit di raccordo, Kit di raccordo XY



INS_SS

Boccola autofilettante
Inox, Inox



VRC2

Staffa di bloccaggio 2
lati, 2 lati



BDP1R

Braccio di reazione,
Serraggio standard



BAB

Perno autobloccante a
sfere, Inox temprato



PTA80

Piede snodato con
base stampata Ø80, Ø
80



M1

Coppia ruota e vite
senza fine, Acciaio
temprato



SEH

Attrezzo di bloccaggio
a tirante, A tirante -
inox



UGH32

Unità di guida tipo H,
Per martinetti Ø 32



TBD

Tavola di
posizionamento a
passo inverso



GCA

Copiglia a scatto, A
scatto



P70

Riduttore a ruota e
vite senza fine, fino a
164 Nm

Prodotti correlati



PRF4545_P

Profilato alluminio per
camera bianca, 45 x
45 mm