


Bracket for aluminium profiles

Stock

PRF **MiniTec**

Support bracket

- Can be used for all types of construction, recommended for use when adding profiles to existing structures
- Use to reinforce structures
- Can be positioned anywhere along the profile length
- For heavy loads, use multiple brackets
- Fixing kit supplied
- Material: grey powder coated aluminium GD

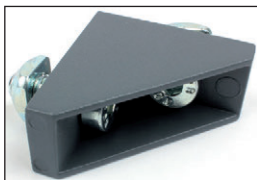


Accessories

- Nut with sprong tab PRF-ECL


Special application

- PRF25-E bracket has a centred section that aligns along profile slot to prevent twisting

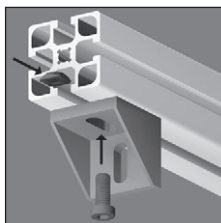


Info.


- *Given for applications using two brackets; when using a single bracket, maximum load is reduced, please contact us for details

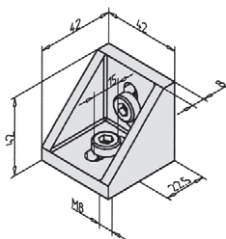

PRF45-E

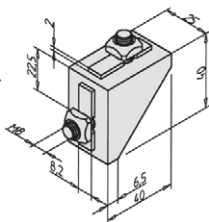

PRF25-E

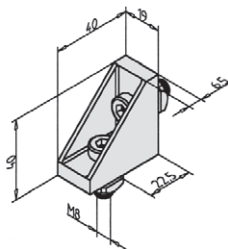

PRF19-E

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	Max. load* (N)	Max. torque (Nm)	For profile	Tightening torque (Nm)	Stock*	Price each 1 to 49
PRF19-E	1200	400	PRF19, PRF32	20	✓	3,98 €
PRF25-E	1200	400	PRF19, PRF32, PRF45	20	✓	4,57 €
PRF45-E	1200	400	PRF45	20	✓	3,98 €

*Depending on availability - Dimensions in mm

Altri prodotti...



VPPTss

Volantino pieno con impugnatura girevole, Inox 304



MAX22

Motoriduttore DC 12V e 24V DC, da 0,07 a 0,2Nm



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato



RNAST

Rotelle, Senza anello interno



SDG_SS

Supporto con tirante ad occhio, Inox



LWL

Guida lineare a sfere - Sfere inox, Carello - da 514 N a 16700 N



SSB

Ingranaggio conico inox, 1:1



RPP

Piastra di giunzione per cinghia RPP, RPP8




MAX26

Motoriduttore DC 12V e 24V DC, da 0,075 a



RTK

Giunto Bowex®, a dentatura bombata,

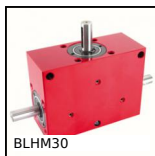

BLHM30

Rinvio angolare, fino a 4.4 Nm



DCA

Ventosa, nitrile

Prodotti correlati



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



PRF_VTM

Fissaggio, Vite testa martello