

Section: 45x32 mm

MiniTecPRF4532


- Profile for creating modular structures
- To be cut to length once supplied
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

### Accessories


- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E, PRF25-E, PRF45-E, PRF4590-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

### Uses

- All types of construction, one side of the profile is covered
- Tables, supports,
- Sliding doors
- Linear guidance

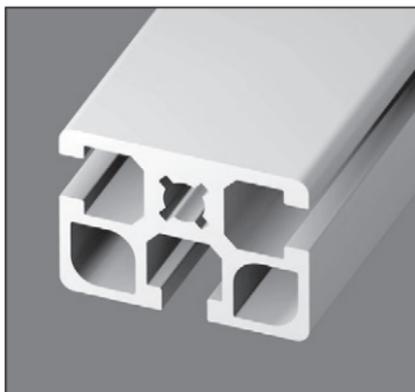

Typical application

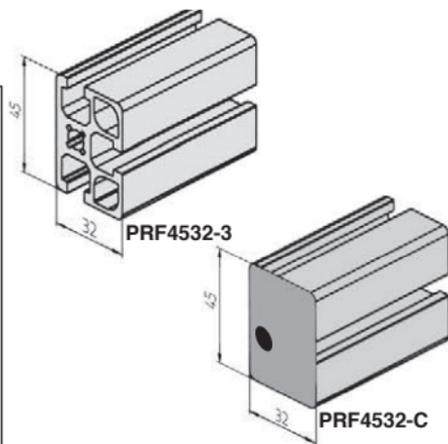

### DISCOUNTS profile DISCOUNTS cover

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	lx (cm <sup>2</sup> )	ly (cm <sup>2</sup> )	Length (mm)	Weight (kg/m)	Stock*	Price each
<b>Profile</b>						
PRF4532-3	10,182	6,492	3000	1,588	✓	83,89 €
<b>Cover</b>						
PRF4532-C		End cover with pin			✓	1,33 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



BPLF

Sfera portante alta sporgenza, Leggero



BG

Giunto Oldham, con vite a pressione



DOMI5

Accessori di collegamento, Piastra



UGCG

Unità di guida per cilindrico, Colonna di guida



CHAB

Hinge with stop, Hinge



BLHB50

Rinvio angolare ad albero cavo, fino a 30 Nm



PSG15

Ingranaggio dritto di precisione, Inox 303



HAR9

Rondella girevole, DIN 6371



ZA

Albero per guida lineare, Acciaio



CLB\_M

Maniglia a ripresa, Zamak



CHMR30

Riduttore a ruota e vite senza fine, fino a 30 Nm



BVR

Battute a vite regolabile, Acciaio

## Prodotti correlati



PRF\_FIX\_UNI

Fissaggio, universale



PRF19\_E

Squadra di giunzione, PRF19 a PRF32