

Stainless steel standard profile

PRF4545 MiniTec

Section: 45x45 mm

- Profile for creating modular structures
- To be cut to length once supplied
- Material: stainless steel 1.4301 (X5 CrNi 18-10)

Accessories

- Universal fixation **PRF-FIX-UNI/SS**
- Stainless steel standard screws (CHC DIN912)
- Stainless steel nuts **PRF-ECL/SS**
- Rod end screw fixing **FHC8-16/SS/B**

Uses

- Food industry
- Outdoor applications
- Chemical industry
- Pharmaceutical industry
- High ambient temperature applications


Advantages

The advantages are the same as for aluminium profiles:

- Same modularity across the complete range
- Slots accept M8 screws
- Compatible with the entire range
- Only 1 type of thread (M8) used across the range
- No special tooling required
- Assemblies can be made in all 4 axes
- Slots can support panels



PRF4545-3/SS

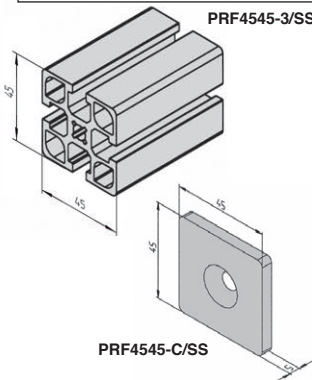

PRF4545-C/SS

DISCOUNTS profile

Qty.	1+	5+	10+
Disc.	List	-5%	On request

DISCOUNTS cover

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	lx (cm ²)	ly (cm ²)	Length (mm)	Weight (kg/m)	Price each
Profile					
PRF4545-3/SS	6,47	6,47	3000	2,778	221,07 €
Cover					
PRF4545-C/SS			End cap		9,97 €

Dimensions in mm

Section: 45x45 mm

MiniTec PRF4545


- Profile for creating modular structures
- To be cut to length once supplied
- PR4545 profile is basic profile for creating all types of structures
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

Accessories


- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E, PRF25-E, PRF45-E, PRF4590-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

Uses

- All types of construction

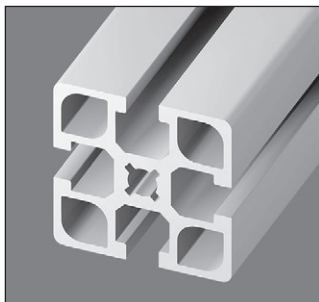

Typical application

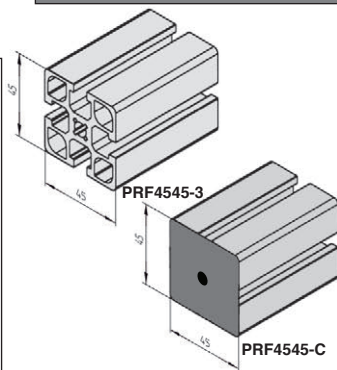

DISCOUNTS profile DISCOUNTS cover

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Ix (cm ⁴)	Iy (cm ⁴)	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF4545-3	14,153	14,153	3000	2,005	✓	72,25 €
Cover						
PRF4545-C		End cover with pin			✓	0,98 €

*Depending on availability - Dimensions in mm

Altri prodotti...



ARTE
Silent block, Carico multidirezionale



HTD8M_20
Puleggia dentata di trasmissione tipo HTD, HTD8 Acciaio



CLB_M
Maniglia a ripresa, Zamak



BPPss
Supporto ritto in lamiera con cuscinetto inox, Inox



GE
Chiusura a leva, Standard



Q3
Cuscinetto a doppia corona di sfere, Obliquo - Acciaio




PRF_BP
Maniglia e battuta per porta, Arresto per porta a battente




MACss
Moschettone inox, Inox



CHAsb28
Cerniera senza perno in rotoli, Cerniera in polimero

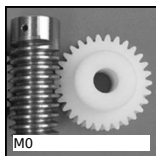

M0
Coppia ruota e vite senza fine, Plastica lavorata (delrin)

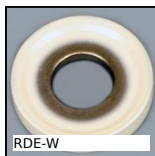

RDE-W
Rondella di tenuta Hygienic Usit®, Inox - EPDM bianco




VDSQ
Bloccaggio scorrevole per la regolazione, Bloccaggio rapido per prof...

Prodotti correlati



PRF_FIX_UNI
Fissaggio, universale

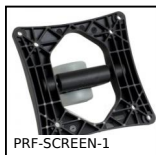

PRF-SCREEN-1
Screen support, Basic support



PRF-SCREEN-4
Screen support, Support with 4 axes of rotation



PRF-SCREEN-5
Screen support, Support with 5 axes of rotation