

# Stainless steel standard profile

## PRF4545 MiniTec

### Section: 45x45 mm

- Profile for creating modular structures
- To be cut to length once supplied
- Material: stainless steel 1.4301 (X5 CrNi 18-10)

### Accessories

- Universal fixation **PRF-FIX-UNI/SS**
- Stainless steel standard screws (CHC DIN912)
- Stainless steel nuts **PRF-ECL/SS**
- Rod end screw fixing **FHC8-16/SS/B**

### Uses

- Food industry
- Outdoor applications
- Chemical industry
- Pharmaceutical industry
- High ambient temperature applications


### Advantages

The advantages are the same as for aluminium profiles:

- Same modularity across the complete range
- Slots accept M8 screws
- Compatible with the entire range
- Only 1 type of thread (M8) used across the range
- No special tooling required
- Assemblies can be made in all 4 axes
- Slots can support panels



PRF4545-3/SS

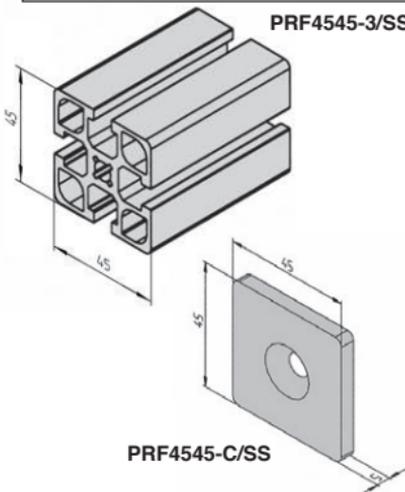

PRF4545-C/SS

### DISCOUNTS profile

Qty.	1+	5+	10+
Disc.	List	-5%	On request

### DISCOUNTS cover

Qty.	1+	50+	100+
Disc.	List	-5%	On request

Part number	lx (cm <sup>2</sup> )	ly (cm <sup>2</sup> )	Length (mm)	Weight (kg/m)	Price each
<b>Profile</b>					
PRF4545-3/SS	6,47	6,47	3000	2,778	221,07 €
<b>Cover</b>					
PRF4545-C/SS			End cap		9,97 €

Dimensions in mm

Section: 45x45 mm

MiniTec PRF4545


- Profile for creating modular structures
- To be cut to length once supplied
- PR4545 profile is basic profile for creating all types of structures
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

### Accessories


- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E, PRF25-E, PRF45-E, PRF4590-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

### Uses

- All types of construction

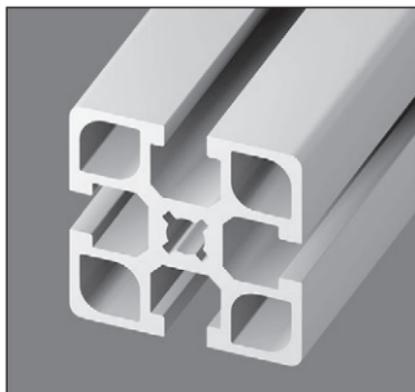

Typical application

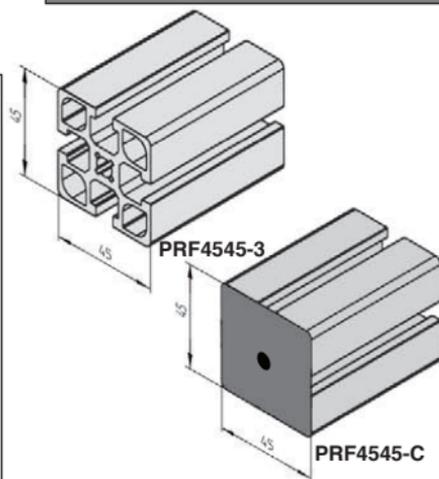

### DISCOUNTS profile DISCOUNTS cover

Qty.	1+	5+	10+
Disc.	List -5%	On request	

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Ix (cm <sup>4</sup> )	Iy (cm <sup>4</sup> )	Length (mm)	Weight (kg/m)	Stock*	Price each
<b>Profile</b>						
PRF4545-3	14,153	14,153	3000	2,005	✓	72,25 €
<b>Cover</b>						
PRF4545-C		End cover with pin			✓	0,98 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



DOMI80

Slitta di regolazione Domini 80, Slitta DOMILINE 80 con contatore e ...



BPPPEBLU

Sfera portante Agro,




HBM

Guida su semi-binari, Boccola di regolazione



HTD14M\_85

Puleggia dentata di trasmissione tipo HTD, HTD14 Acciaio

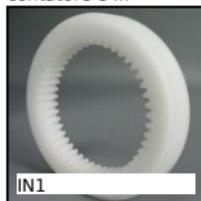

IN1

Ingranaggio interno, Plastica lavorata (delrin)




HTD8M-BAR

Barra dentata per cinghia RPP, HTD8



H3

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2

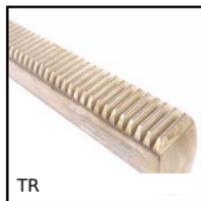

TR

Cremagliera sezione circolare, Inox - modulo 0,25-1,5



P15

Riduttore a ruota e vite senza fine, fino a 3,75 Nm



CHMX\_CHMDX

Albero per riduttore a ruota e vite senza fine CHMR e CHM, Albero se...



BLHB30

Rinvio angolare ad albero cavo, fino a 4.47 Nm



BCFH

Pomello a fungo Hygienic Usit®, Con perno filettato e collare alto

## Prodotti correlati



PRF\_FIX\_UNI

Fissaggio, universale



PRF-SCREEN-1

Screen support, Basic support



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation