



Aluminium profile with "extendable slot"

Section: 45x45 mm **MiniTec** PRF4545P

- Profile for creating modular structures
- Slots of the required length can be opened on any face
- To be cut to length once supplied
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details

Accessories




- Universal fastener **PRF-FIX-UNI**
- Right angle **PRF19-E, PRF25-E, PRF45-E, PRF4590-E**
- Standard fastener **PRF-FIX-STD**
- Screwed-in assemblies

Tools

- Stripper **PRF-TOOL-OR**
- Trimmer **PRF-TOOL-EB**

Uses

- All types of construction, especially where strict hygiene rules must be adhered to, such as the food or pharmaceutical industries
- Central of the profile can be used as a channel for a counterweight

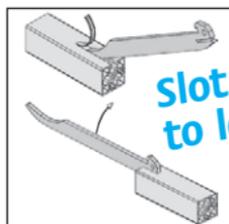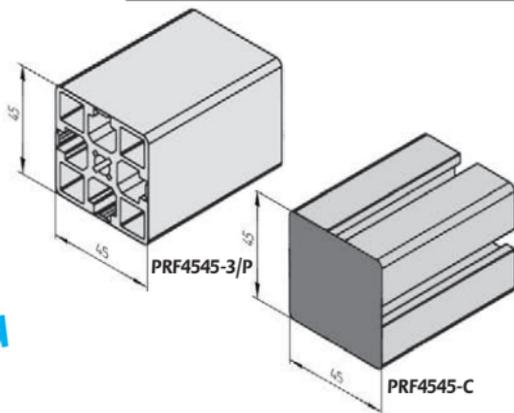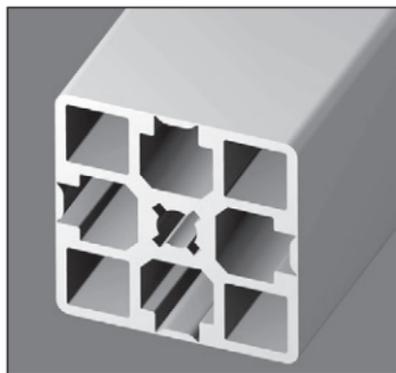

Slot opened to length

DISCOUNTS profile DISCOUNTS cover

| | | | |
|-------|----------|----|------------|
| Qty. | 1+ | 5+ | 10+ |
| Disc. | List -5% | | On request |

| | | | |
|-------|----------|-----|------------|
| Qty. | 1+ | 50+ | 100+ |
| Disc. | List -5% | | On request |

| Part number | lx (cm ⁴) | ly (cm ⁴) | Length (mm) | Weight (kg/m) | Stock* | Price each |
|----------------|-----------------------|-----------------------|-------------|---------------|--------|------------|
| Profile | | | | | | |
| PRF4545-3/P | 14,095 | 14,095 | 3000 | 2,01 | ✓ | 86,30 € |
| Cover | | | | | | |
| PRF4545-C | | End cap | | | ✓ | 0,98 € |
| PRF45-EG | | Fixing cover | | | ✓ | 0,67 € |
| Tools | | | | | | |
| PRF-TOOL-OR | | Stripper | | | ✓ | 24,05 € |
| PRF-TOOL-EB | | Deburring tool | | | - | 125,14 € |

*Depending on availability - Dimensions in mm

Altri prodotti...



LVT

Mini martinetto motorizzato 1A, 1 ampere




SVR15

Martinetto a vite - Vite rotante, Con madrevite esterna



BABPass

Perno autobloccante inox temprato ad anello, Con impugnatura ad

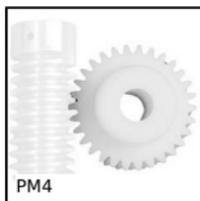

PM4

Ruota per vite senza fine, Plastica lavorata (delrin)



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



OP7

Indicatore di posizione digitale (N. di giri), 5 cifre



PCS_PA6

, 12.7mm (DIN 08B-1)



T10_21_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...



BEK

Vite a ricircolo di sfere miniatura, Supporto



RJA00_02

Guarnizione in gomma, Da agganciare



ACLEFS

Elementi di ancoraggio, Standard



PRF_PSA

Rotella per profilo alluminio, Albero per guida

Prodotti correlati



PRF_FIX_UNI

Fissaggio, universale