

# R90° aluminium profile

## PRF4545R90

## Section: 45x45mm

- Profile for modular structures
- To be cut to length by the user
- Material:  
Anodised aluminium
- Caps are not supplied individually, contact us for details

### Mounting alternatives


- PRF-FIX-UNI universal fastener
- PRF19-E angle bracket
- PRF-FIX-STD standard fastener
- Screwed assemblies

### Application


- For use with any type of modular construction

### Advantage


- Eliminates projecting edges

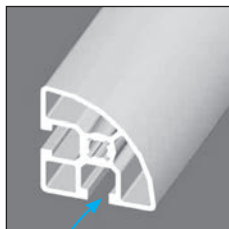

8mm slot

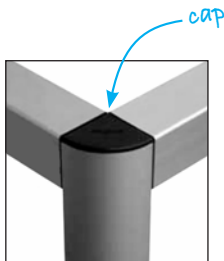

cap

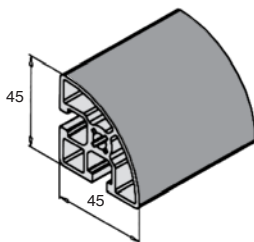

### DISCOUNTS profile

Qty	1+	5+	10+
Disc.	List	-5%	On request

### DISCOUNTS cap

Qty	1+	50+	100+
Disc.	List	-5%	On request


Part number	lx (cm <sup>4</sup> )	ly (cm <sup>4</sup> )	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF4545-3-R90	9,138	9,138	3000	1,478	4	79,98 €
Cap						
PRF4545-R90-C		End cap with pin			-	3,84 €

Dimensions in mm

## Altri prodotti...



PC5375S  
Pignone a catena -  
Inox, 9.525 (DIN  
06B-1)

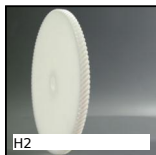


H2  
Ingranaggio elicoidale  
ad assi incrociati a  
90°, Plastica lavorata



BPHF  
Sfera portante, Forte



EHD08-3  
Riduttore coassiale,  
da 20 a 50 Nm

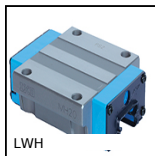

LWH  
Guida lineare a sfere -  
Sfere acciaio, Carello -  
da 9320 N a 71300 N



PGM52-M4  
Maniglia a ponte,  
Ottone



SVG  
Chiusura a leva  
regolabile, Corsa da  
106,7mm a 121,4mm



P55  
Riduttore a ruota e  
vite senza fine, fino a  
57 Nm



BABtss  
Perno autobloccante  
inox 303, Inox 303



DOMI30  
Slitta di regolazione  
Domino 30, Slitta  
DOMILINE 30



MEB  
Ingranaggio conico in  
plastica stampata, 1:1



AC144  
Piastrina di riscontro  
piatta per chiusura,  
22mm

## Prodotti correlati



PRF4545  
Profilato alluminio  
standard, 45 x 45 mm



PRF\_ECL  
Fissaggio, Dado  
quadrato con  
linguetta - Acciaio



PRF\_FIX\_STD  
Fissaggio, Fissaggio  
standard



PRF\_FIX\_UNI  
Fissaggio, universale