

Standard aluminium profile



PRF4590 **MiniTec**

Section: 45x90 mm

- Profile for creating modular structures
- To be cut to length once supplied
- PRF4590 is the basic profile for creating all types of constructions
- Material: anodised aluminium
- Covers are not sold individually, please contact us for details




Accessories


- Universal fastener PRF-FIX-UNI
- Right angle PRF19-E, PRF25-E, PRF45-E, PRF4590-E
- Standard fastener PRF-FIX-STD
- Screwed-in assemblies

Uses

- Can be used for constructing any type of assembly
- Central of the profile can be used as a channel for a counterweight

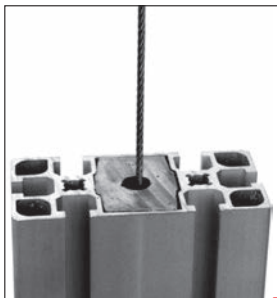

Typical application

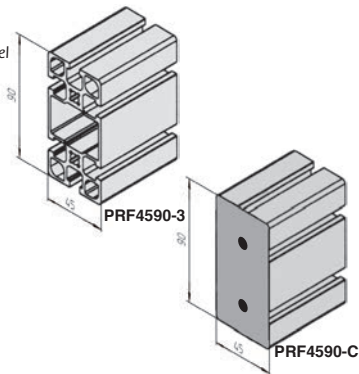

DISCOUNTS profile

DISCOUNTS cover

Qty	1+	5+	10+
Disc.	List	-5%	On request

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	lx (cm ²)	ly (cm ²)	Length (mm)	Weight (kg/m)	Stock*	Price each
Profile						
PRF4590-3	100,842	24,321	3000	3,134	✓	150,61 €
Cover						
PRF4590-C		End cover with pin			✓	1,72 €

*Depending on availability - Dimensions in mm

Our other products




TIFss

Threaded stud -
DIN976A, Stainless
steel



CHM50

Worm and wheel gear
reducer, up to 107
Nm

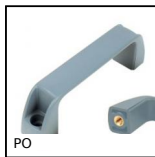

PO

Pull handle - Multi-
sector, Tapped
recessed insert



BABV

Ball lock pins lockable
, Stainless steel



LR

Precision locknut,
Precision locknut



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1



WS20

Drylin® W rail, Rail



AKD

Bellows coupling
Gerwah®, from 22 to
600Nm



ESCON

Speed controller 5A
accessories, Kit of 4
cables for DC motor



PTRSS

Idle chain sprocket,
For hostile
environments



UGH40

H Type Guide units,
For Ø40 actuators



VB

Small 6 lobe threaded
handle - female,
Duroplast - Stainless
steel

Complementary products



PRF_FIX_UNI

Universal fastener for
aluminium profile,
Universal



PRF4590_E

Bracket for aluminium
profile, PRF4590



BAC105

Storage bin, 8mm



BAC105

Storage bin, 8mm

Altri prodotti...



MSP3815
 Inserto con piastrina a incollare Masterplate®, rettangolare con in...



SVG
 Chiusura a leva regolabile, Corsa da 118mm a 130,5mm



CMM_SS
 Testa a snodo maschio DIN ISO12240-4, Inox / bronzo - Série



PRF_PSA
 Rotella per profilo alluminio, Albero per guida



PR65C
 Half-articulated foot Ø 65, Ø 65




CHTRP
 Riduttore a rinvio angolare a L o a T, fino a 87,3 Nm



CHC
 Vite a testa cava esagonale CHC, Acciaio classe 12.19




WJUM20
 Pattino Drylin® W, Pattino

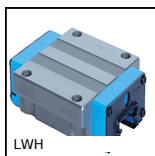

LWH
 Guida lineare a sfere - Sfere acciaio, Carello - da 9320 N a 71300 N



PR105
 Piede fissabile con snodo - poliammide, Ø 103

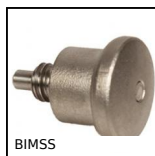

BIMSS
 Pistoncino a molla, Miniatura inox



BPM
 Pressore a molla con intaglio e puntale a sfera, Acciaio

Prodotti correlati



PRF_FIX_UNI
 Fissaggio, universale



PRF4590_E
 Squadra di giunzione, PRF4590



BAC105
 Contenitore a becco, 8mm



BAC105
 Contenitore a becco, 8mm