

 


Dual lock for use on aluminium profile

Quick fitting, self blocking door lock

PRFSRAD

- Door or trap lock for structures assembled from PRF4545 aluminium profiles
- Mounts on central support and allows 2 doors to be locked separately
- Material: Die cast aluminium housing with black finish



No machining required




Advantages



- Easy to mount from the front using M6 CHC screws
- No drilling required
- Security feature: Cannot be removed when in locked position

Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

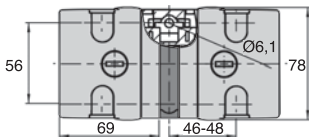

NEW!

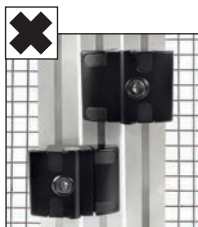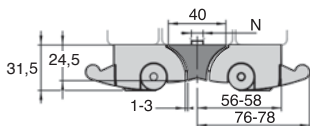

More aesthetic and more economical

DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	Type	For slot N	Weight (g)	Price each
PRF-SRAD-78-A	With universal key	8/10	235,5	62,28 €
PRF-SRAD-78-B	With individual key	8/10	235,5	62,28 €

Dimensions in mm

Altri prodotti...



CHAE3030PA

Cerniera ad avvitare
estetica quadrata,
Poliammide



PTR

Pignone tendicatena,
Per applicazioni
correnti



PRF1932

Profilato alluminio
standard, 19 x 32 mm




SF_ZZ

Cuscinetto radiale a
sfere, Inox



PV2R

Braccio portaventosa
orientabile, Serraggio
rinforzato

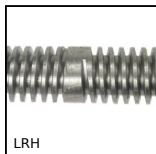

LRH

Vite trapezoidale a
doppia inclinazione, a
doppia inclinazione - 1
f...




PGB

Attrezzi, Porta attrezzi



HG6

Ingranaggio dritto
acciaio, Acciaio
20NCD2

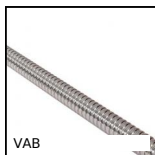

VAB

Vite a ricircolo di sfere
al metro, Vite a sfere
rullata, al metro



MC

Deceleratore,
autocompensante -
senza regolazione



M1

Coppia ruota e vite
senza fine, Acciaio
non temprato



M1

Coppia ruota e vite
senza fine, Acciaio
temprato

Prodotti correlati



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Acciaio



PRF4545

Profilato alluminio
standard, 45 x 45 mm