

 


Dual lock for use on aluminium profile

Quick fitting, self blocking door lock

PRFSRAD

- Door or trap lock for structures assembled from PRF4545 aluminium profiles
- Mounts on central support and allows 2 doors to be locked separately
- Material: Die cast aluminium housing with black finish



No machining required




Advantages



- Easy to mount from the front using M6 CHC screws
- No drilling required
- Security feature: Cannot be removed when in locked position

Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

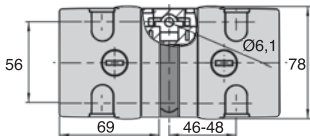

NEW!

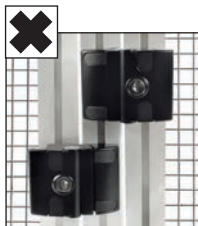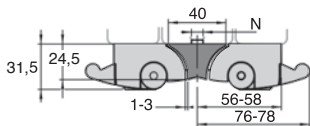

More aesthetic and more economical

DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	Type	For slot N	Weight (g)	Price each
PRF-SRAD-78-A	With universal key	8/10	235,5	62,28 €
PRF-SRAD-78-B	With individual key	8/10	235,5	62,28 €

Dimensions in mm

Altri prodotti...



RPCplss
Ruota fissa con piastra, Inox - Poliammide



PW_PWG15
Vite senza fine di precisione, Inox



MDB_MTB
Ingranaggio conico in plastica stampata, 2:1



GAL21
Ruota per trasportatore, Plastica



BLHB30
Rinvio angolare ad albero cavo, Fino a 4.4 Nm



CHAL3
Cerniera piana, Alluminio



PPD
Pistoncino a molla, Per lamiera



PPRss
Piastrina con anello, Inox



FDSQ
Flexible drive shaft, Masterflex® Steel,



PRF_CHA
Cerniera ad avvitare, Su facciata



CHAPAMss
Cerniera a testa piatta a saldare, Inox o



CHA135
Cerniera ad avvitare, 135 gradi

Prodotti correlati



PRF_ECL
Fissaggio, Dado quadrato con linguetta - Acciaio



PRF4545
Profilato alluminio standard, 45 x 45 mm