




Dual lock for use on aluminium profile

Quick fitting, self blocking door lock

PRFSRAD

- Door or trap lock for structures assembled from PRF4545 aluminium profiles
- Mounts on central support and allows 2 doors to be locked separately
- Material: Die cast aluminium housing with black finish

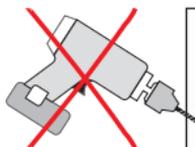

No machining required




Advantages



- Easy to mount from the front using M6 CHC screws
- No drilling required
- Security feature: Cannot be removed when in locked position

Accessories

- CHC6-16 screws and PRF-ECL-M6 channel mounting nuts not supplied

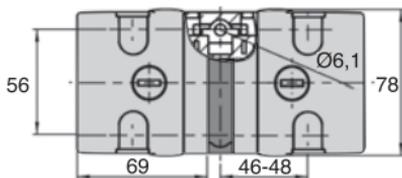

NEW!

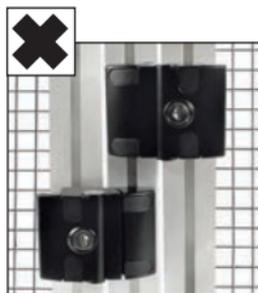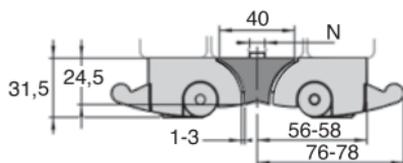

More aesthetic and more economical

DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%	On request	

Part number	Type	For slot N	Weight (g)	Price each
PRF-SRAD-78-A	With universal key	8/10	235,5	62,28 €
PRF-SRAD-78-B	With individual key	8/10	235,5	62,28 €

Dimensions in mm

Altri prodotti...



SRG

Chiusura a leva regolabile, Corsa da 96mm a 121,7mm




EHD04

Riduttore coassiale, da 3.4 a 7 Nm



ATZYSS

Antivibrante elastico inox sfolato, Inox

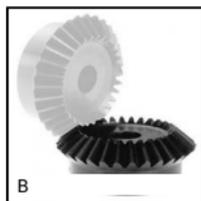


B

Ingranaggio conico - Acciaio 60C40, 1:1



ZG1

Ingranaggio dritto in plastica, Plastica lavorata (delrin)

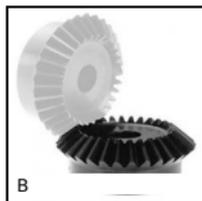

B

Ingranaggio conico - Acciaio 60C40, 1:1



CHAFR-MINI

Cerniera, A frizione



SLB

Pistoncino a molla, acciaio classe 5.8



PGR

Impugnatura cilindrica libera retraibile, Retraibile



TS01_TW01

Guida lineare su binario Drylin® T, fino al 7000 N



LVT

Mini martinetto motorizzato 1A, 1 ampere



HSSss

Vite a spalla di precisione inox ISO7379, Inox ISO 7379

Prodotti correlati



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



PRF4545

Profilato alluminio standard, 45 x 45 mm