

# Emergency release button

New

PRF<sub>BOU</sub>

For use with profile locks

- **Emergency release button allows security doors fitted with PRF-SRA-CAP locks to be opened**
- Secured using CHC M6 screws
- Materials:
  - Button: glass fibre reinforced PA nylon
  - Plate: chromed steel
- Working temp range: -20° to 55 °C

## Advantages


- Ideal for opening the door from the inside if there is a risk of an operator becoming trapped
- Can be mounted on 30, 40, 45 or 50 mm section profiles
- Ideal accessory for the PRF-SRA-CAP lock

## Accessories

- PRF-ECL-M6 screws



Typical application

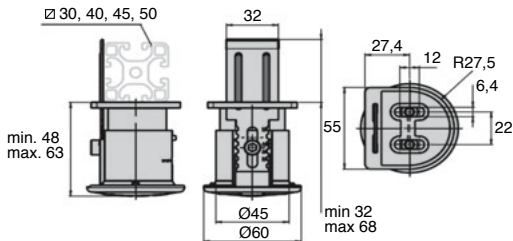

## DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%		On request

Part number	Weight (g)	Price each
PRF-BOU-URG	110,8	30,90 €

Dimensions in mm

## Altri prodotti...



PW\_PWG3  
Vite senza fine di  
precisione, Inox



EAR  
Cuscinetti a sfere -  
Accessorio, Ghiera  
autobloccante - anello  
di fr...



SCE  
Serracavo, Acciaio



DB\_ECO  
Ingranaggio conico -  
Acciaio C43 - ECO, 2:1




KB\_OP  
Manicotto a sfere di  
precisione, Di  
precisione - acciaio



Gdal  
Giunto cardanico  
doppio serie eco,  
Sollecitazioni leggere



YG1  
Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6

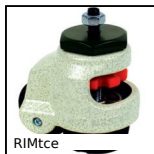

RIMtce  
Ruota di livellamento,  
Con foro centrale



NTMdl  
Grano punta in delrin,  
punta in delrin



PW\_PWG25  
Vite senza fine di  
precisione, Inox



RHTplss  
Ruota alte  
temperature, fino a  
200kg



COA-COG  
Staffa di montaggio  
per molla a gas,  
Staffa di montaggio  
piana per s...

## Prodotti correlati



PRF4545  
Profilato alluminio  
standard, 45 x 45 mm