

# Emergency release button

New

PRF<sub>BOU</sub>

For use with profile locks

- **Emergency release button allows security doors fitted with PRF-SRA-CAP locks to be opened**
- Secured using CHC M6 screws
- Materials:
  - Button: glass fibre reinforced PA nylon
  - Plate: chromed steel
- Working temp range: -20° to 55 °C

## Advantages


- Ideal for opening the door from the inside if there is a risk of an operator becoming trapped
- Can be mounted on 30, 40, 45 or 50 mm section profiles
- Ideal accessory for the PRF-SRA-CAP lock

## Accessories

- PRF-ECL-M6 screws



Typical application

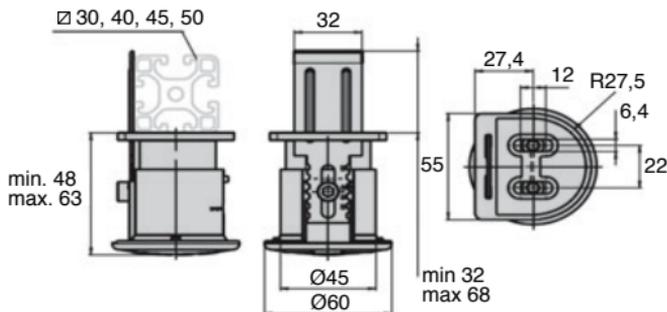

## DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%		On request

Part number	Weight (g)	Price each
PRF-BOU-URG	110,8	30,90 €

Dimensions in mm

## Altri prodotti...



RTN  
Giunto Bowex ®, a dentatura bombata, Nylon



PR65C  
Half-articulated foot Ø 65, Ø 65



BEAS  
Star shaped anti-static handle, Star, anti-static



CHB  
Feet, For CHB gearbox



KB\_OP  
Manicotto a sfere di precisione, Di precisione - acciaio



VELM4  
Supporto avvitabile per rotolo a strappo fermacavi, Poliammide



KKSS  
Chiavetta rettangolare, Inox



SLH  
Attrezzo di bloccaggio a leva orizzontale, A leva orizzontale - acci...




PRF1932  
Profilato alluminio standard, 19 x 32 mm



WBGV  
Anello di sollevamento, Con grillo ad avvitare



NPR  
Morsetto porta catarifrangente,

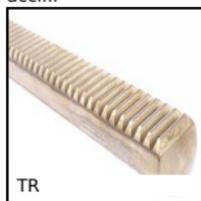

TR  
Cremagliera sezione circolare, Inox - modulo 0,25-1,5

## Prodotti correlati



PRF4545  
Profilato alluminio standard, 45 x 45 mm