

# Emergency release button

New

PRF<sub>BOU</sub>

For use with profile locks

- **Emergency release button allows security doors fitted with PRF-SRA-CAP locks to be opened**
- Secured using CHC M6 screws
- Materials:
  - Button: glass fibre reinforced PA nylon
  - Plate: chromed steel
- Working temp range: -20° to 55 °C

## Advantages


- Ideal for opening the door from the inside if there is a risk of an operator becoming trapped
- Can be mounted on 30, 40, 45 or 50 mm section profiles
- Ideal accessory for the PRF-SRA-CAP lock

## Accessories

- PRF-ECL-M6 screws



Typical application

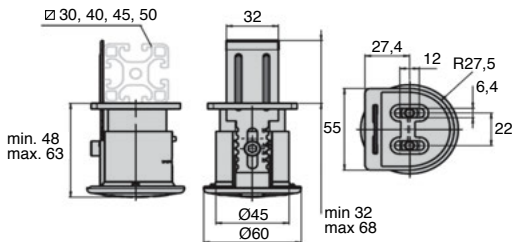

## DISCOUNTS

Qty	1+	2+	5+
Disc. List	-5%		On request

Part number	Weight (g)	Price each
PRF-BOU-URG	110,8	30,90 €

Dimensions in mm

## Altri prodotti...




WJUM20  
Pattino Drylin® W,  
Pattino



METEB  
Barre autolubrificanti,  
Bronzo BP25



PW\_PWG3  
Vite senza fine di  
precisione, Inox

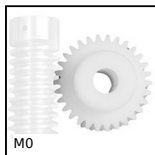


M0  
Coppia ruota e vite  
senza fine, Plastica  
lavorata (delrin)



ACM\_TRI  
Tirante chiusura in  
gomma, Caucciù



VQT  
Chiusura 1/4 di giro per  
bloccaggio, Manopola  
plastica o inox

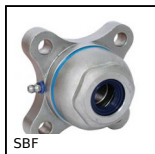


SBF  
Open flange bearing  
unit for food industry,  
cover



BPLE  
Sfera portante a  
incastro, Leggero



CHINV  
Cerniera invisibile,  
Invisibile - Apertura

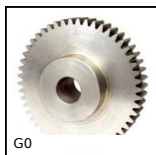

G0  
Ingranaggio dritto  
acciaio, Acciaio



VLBS  
Anello di  
sollevamento,  
Anello di sollevamento



PSG055  
Ingranaggio dritto di  
precisione, Inox 303

## Prodotti correlati



PRF4545  
Profilato alluminio  
standard, 45 x 45 mm