

# Flexible tube handle



## PSPT

For Ø18 - Ø33 tubes



- Tube handle with collar
- Smooth interior
- Material:  
Black PVC

### Assembly


- Fit using a mallet,  
no adhesive required

### Advantages

- Resists oil, shocks and low temperatures

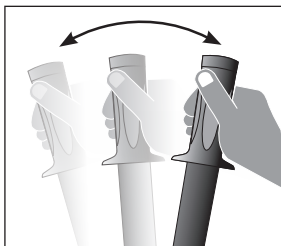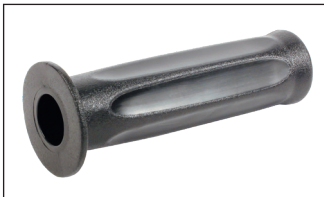

Typical application

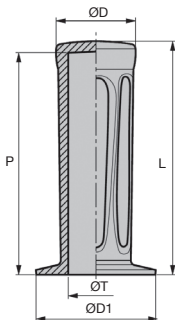

### DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube		ØD	ØD1	P	Weight (g)	Stock*	Price each 1 to 59
	ØT	L						
PSPT18-115	18-19	115	31	44	110	62	✓	3,15 €
PSPT20-115	20-21	115	31	44	110	56	✓	2,79 €
PSPT22-115	22-23	115	31	44	110	46	✓	2,42 €
PSPT24-125	24-25	125	36	49	120	72	✓	3,60 €
PSPT26-125	26	125	36	49	120	60	✓	3,15 €
PSPT27-125	27-28	125	36	49	120	50	✓	3,03 €
PSPT29-125	29	125	36	49	120	50	✓	3,03 €
PSPT30-130	30	130	42	51	125	92	✓	3,60 €
PSPT33-130	33	130	42	51	125	74	✓	3,15 €

\*Depending on availability - Dimensions in mm

# Conical flexible shaft handle Ø20

For shafts Ø6 to Ø12


PSPE20

## Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

## Assembly

- Fit using a mallet, no adhesive required

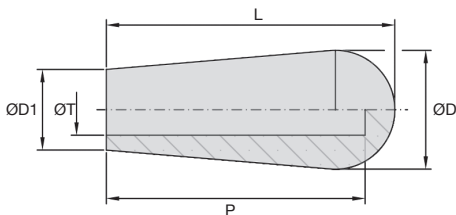

## DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each 1 to 59
PSPE20-43-6	20	14	6	43	40	11	-	1,74 €
PSPE20-43-7	20	14	7	43	40	10	-	1,65 €
PSPE20-43-8	20	14	8	43	40	10	-	1,59 €
PSPE20-43-10	20	14	10	43	40	9	-	1,53 €
PSPE20-43-12	20	14	12	43	40	8	-	1,47 €

\*Depending on availability - Dimensions in mm

HPC

CAT NEW  
01/2023

www.hpceurope.com

Tel. +33(0)4 37 496 496

# Conical flexible shaft handle Ø22

## PSPE22


For shafts Ø7 to Ø14

### Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

### Assembly

- Fit using a mallet, no adhesive required

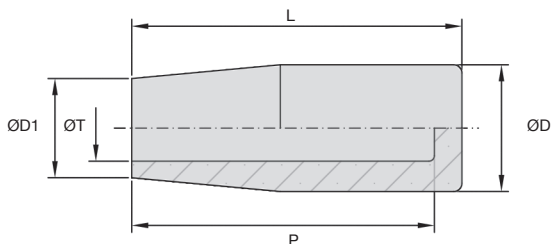

### DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each
								1 to 59
PSPE22-60-7	22	17	7	60	58	24	-	2,76 €
PSPE22-60-8	22	17	8	60	58	23	-	2,58 €
PSPE22-60-9	22	17	9	60	58	23	-	2,49 €
PSPE22-60-10	22	17	10	60	58	22	-	2,43 €
PSPE22-60-12	22	17	12	60	58	21	-	2,31 €
PSPE22-60-14	22	17	14	60	58	20	-	2,25 €

\*Depending on availability - Dimensions in mm

# Flexible tube handle

For tubes Ø12 to Ø22

PSPD18

## Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

## Assembly


- Fit using a mallet, no adhesive required

## Advantages

- Ergonomic handle for excellent grip

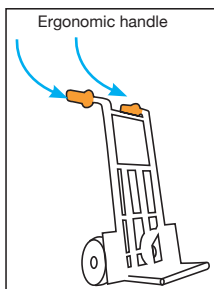

Typical application

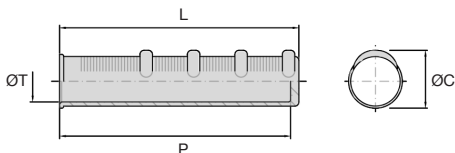

## DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	L	ØT	ØC	P	Weight (g)	Stock*	Price each 1 to 59
PSPD18-118-12	118	12	28	113	52	-	4,14 €
PSPD18-118-14	118	14	28	113	45	-	3,84 €
PSPD18-118-16	118	16	28	113	40	-	3,54 €
PSPD18-118-18	118	18	28	113	35	-	3,18 €
PSPD18-118-20	118	20	28	113	28	-	2,43 €
PSPD18-118-21	118	21	28	113	26	-	2,25 €
PSPD18-118-22	118	22	28	113	22	-	2,07 €
PSPD18-118-22L	118	22	28	113	19	-	2,13 €

\*Depending on availability - Dimensions in mm

# Flexible tube handle

## PSPD40

## For tubes Ø18 and Ø22

### Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

### Assembly

- Fit using a mallet, no adhesive required

### Advantages

- Ergonomic handle for excellent grip

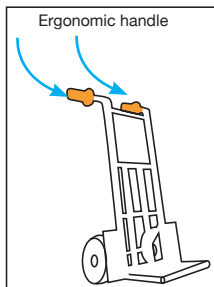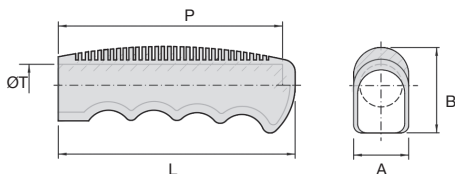

Typical application

### DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	L	A	B	ØT	P	Weight (g)	Stock*	Price each 1 to 59
PSPD40-112-18	112	26	40	18	106	49	-	4,59 €
PSPD40-112-22	112	26	40	22	106	47	-	4,59 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



VB

Volantino a 6 lobi,  
Duroplast - Inox



PSG125S

Ingranaggio dritto di  
precisione, Inox 316



PTA40

Articulated foot with  
solid base foot Ø 40,  
30000N



UCP\_PBT

Cuscinetto ritto  
polimero inox,  
polimero e inox



PM2

Coppia ruota e vite  
senza fine, Acciaio  
non temprato



GARBAB

Perno di bloccaggio  
rapido manuale, A  
sfere



VPRA\_M

Volantino con  
impugnatura, Plastica  
termoindurente -  
Mozzo:inox



PLA

Magnete, Magnete  
piatto con filettatura



ZDB

Ingranaggio conico in  
plastica, 2:1



CHAR7530

Cerniera a molla,  
saldabile



PTA50

Piede snodato con  
base stampata Ø50, Ø



TIFss

Tirante tutto filetto -  
DIN976A, Inox

## Prodotti correlati




PSPT

Manopola a pressione,  
PVC



PSPD40

Manopola a pressione,  
PVC nero

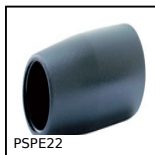

PSPE22

Conical flexible shaft  
handlee Ø22, Black  
PVC



PSPE20

Conical flexible shaft  
handle Ø20, Black  
PVC