

Flexible tube handle



PSPT

For Ø18 - Ø33 tubes


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet,
no adhesive required

Advantages

- Resists oil, shocks and low temperatures

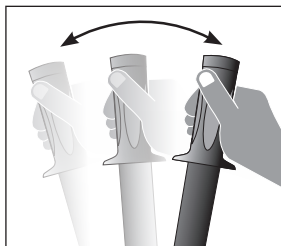

Typical application

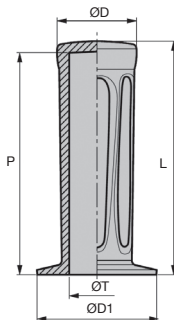

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube		ØD	ØD1	P	Weight (g)	Stock*	Price each 1 to 59
	ØT	L						
PSPT18-115	18-19	115	31	44	110	62	✓	3,15 €
PSPT20-115	20-21	115	31	44	110	56	✓	2,79 €
PSPT22-115	22-23	115	31	44	110	46	✓	2,42 €
PSPT24-125	24-25	125	36	49	120	72	✓	3,60 €
PSPT26-125	26	125	36	49	120	60	✓	3,15 €
PSPT27-125	27-28	125	36	49	120	50	✓	3,03 €
PSPT29-125	29	125	36	49	120	50	✓	3,03 €
PSPT30-130	30	130	42	51	125	92	✓	3,60 €
PSPT33-130	33	130	42	51	125	74	✓	3,15 €

*Depending on availability - Dimensions in mm

Conical flexible shaft handle Ø20

For shafts Ø6 to Ø12


PSPE20

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

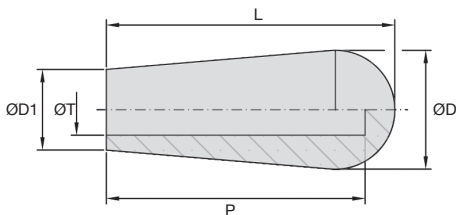

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each 1 to 59
PSPE20-43-6	20	14	6	43	40	11	-	1,74 €
PSPE20-43-7	20	14	7	43	40	10	-	1,65 €
PSPE20-43-8	20	14	8	43	40	10	-	1,59 €
PSPE20-43-10	20	14	10	43	40	9	-	1,53 €
PSPE20-43-12	20	14	12	43	40	8	-	1,47 €

*Depending on availability - Dimensions in mm

HPC

CAT NEW
01/2023

www.hpceurope.com

Tel. +33(0)4 37 496 496

Conical flexible shaft handle Ø22

PSPE22


For shafts Ø7 to Ø14

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

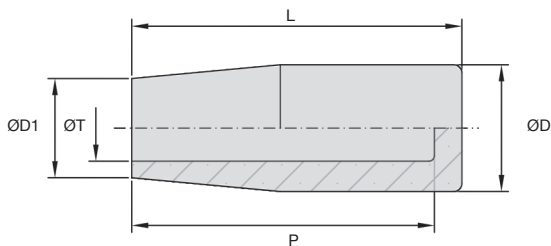

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each
								1 to 59
PSPE22-60-7	22	17	7	60	58	24	-	2,76 €
PSPE22-60-8	22	17	8	60	58	23	-	2,58 €
PSPE22-60-9	22	17	9	60	58	23	-	2,49 €
PSPE22-60-10	22	17	10	60	58	22	-	2,43 €
PSPE22-60-12	22	17	12	60	58	21	-	2,31 €
PSPE22-60-14	22	17	14	60	58	20	-	2,25 €

*Depending on availability - Dimensions in mm

Flexible tube handle

For tubes Ø12 to Ø22

PSPD18

Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

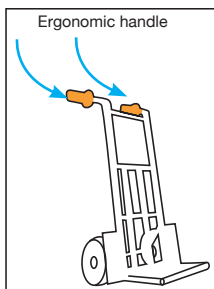

Typical application

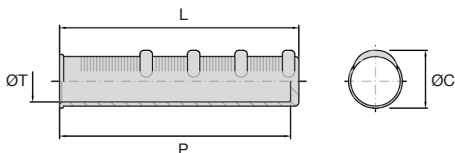

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	L	ØT	ØC	P	Weight (g)	Stock*	Price each 1 to 59
PSPD18-118-12	118	12	28	113	52	-	4,14 €
PSPD18-118-14	118	14	28	113	45	-	3,84 €
PSPD18-118-16	118	16	28	113	40	-	3,54 €
PSPD18-118-18	118	18	28	113	35	-	3,18 €
PSPD18-118-20	118	20	28	113	28	-	2,43 €
PSPD18-118-21	118	21	28	113	26	-	2,25 €
PSPD18-118-22	118	22	28	113	22	-	2,07 €
PSPD18-118-22L	118	22	28	113	19	-	2,13 €

*Depending on availability - Dimensions in mm

Flexible tube handle

PSPD40

For tubes Ø18 and Ø22

Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

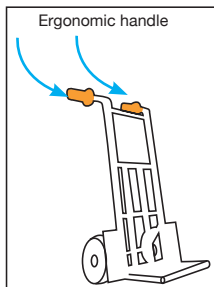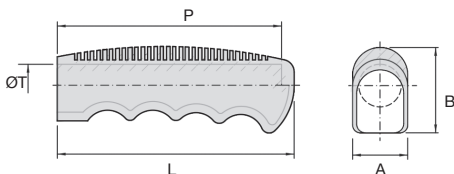

Typical application

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	L	A	B	ØT	P	Weight (g)	Stock*	Price each 1 to 59
PSPD40-112-18	112	26	40	18	106	49	-	4,59 €
PSPD40-112-22	112	26	40	22	106	47	-	4,59 €

*Depending on availability - Dimensions in mm

Altri prodotti...



GCL

Guida lineare a sfere -
Sfere inox, Carello -
da 516 N a 8396 N



TK_UUOP

Manicotto a sfere
autoallineante
Topball,
Autoallineante Topball



GLB

Volantino a 6 lobi,
Tecnopolimero -
Ottone



SSBRA

Ingranaggio conico
inox, 1:1



GE14

Chiusura a leva, Con
porta-lucchetto



WS16

Binario Drylin® W,
Binario



CQA30

Accessori per slitta di
regolazione miniatura,
30



BFDdII

Boccola di fermo per
rotto ad innesto,
Acciaio nichelato



ASL

Anello di
sollevamento, a 45° a
saldare



MEB

Ingranaggio conico in
plastica stampata, 1:1



GTCCS

Rullo tendicinghia, Per
ambienti aggressivi



PSG08HC

Ingran. dritto di
precisione trattato
skiving, Acciaio
20NCD2 cement...

Prodotti correlati



PSPT

Manopola a pressione,
PVC



PSPD40

Manopola a pressione,
PVC nero



PSPE22

Conical flexible shaft
handlee Ø22, Black
PVC



PSPE20

Conical flexible shaft
handle Ø20, Black
PVC