

Flexible tube handle



PSPT

For Ø18 - Ø33 tubes


- Tube handle with collar
- Smooth interior
- Material:
Black PVC

Assembly


- Fit using a mallet,
no adhesive required

Advantages

- Resists oil, shocks and low temperatures

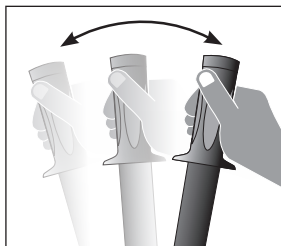

Typical application

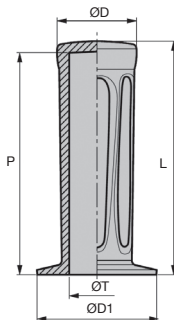

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Tube		ØD	ØD1	P	Weight (g)	Stock*	Price each 1 to 59
	ØT	L						
PSPT18-115	18-19	115	31	44	110	62	✓	3,15 €
PSPT20-115	20-21	115	31	44	110	56	✓	2,79 €
PSPT22-115	22-23	115	31	44	110	46	✓	2,42 €
PSPT24-125	24-25	125	36	49	120	72	✓	3,60 €
PSPT26-125	26	125	36	49	120	60	✓	3,15 €
PSPT27-125	27-28	125	36	49	120	50	✓	3,03 €
PSPT29-125	29	125	36	49	120	50	✓	3,03 €
PSPT30-130	30	130	42	51	125	92	✓	3,60 €
PSPT33-130	33	130	42	51	125	74	✓	3,15 €

*Depending on availability - Dimensions in mm

Conical flexible shaft handle Ø20

For shafts Ø6 to Ø12


PSPE20

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

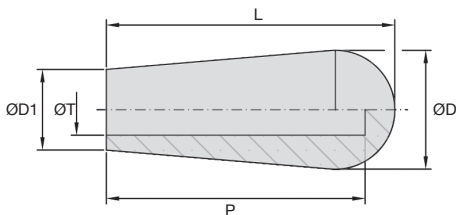

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each 1 to 59
PSPE20-43-6	20	14	6	43	40	11	-	1,74 €
PSPE20-43-7	20	14	7	43	40	10	-	1,65 €
PSPE20-43-8	20	14	8	43	40	10	-	1,59 €
PSPE20-43-10	20	14	10	43	40	9	-	1,53 €
PSPE20-43-12	20	14	12	43	40	8	-	1,47 €

*Depending on availability - Dimensions in mm

Conical flexible shaft handle Ø22

PSPE22


For shafts Ø7 to Ø14

Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

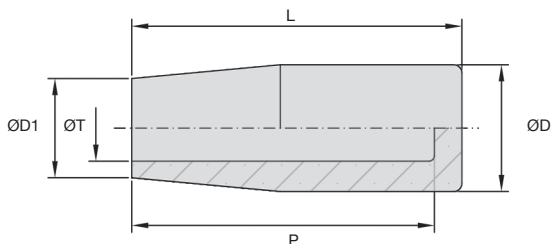

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØT	L	P	Weight (g)	Stock*	Price each
							1 to 59	
PSPE22-60-7	22	17	7	60	58	24	-	2,76 €
PSPE22-60-8	22	17	8	60	58	23	-	2,58 €
PSPE22-60-9	22	17	9	60	58	23	-	2,49 €
PSPE22-60-10	22	17	10	60	58	22	-	2,43 €
PSPE22-60-12	22	17	12	60	58	21	-	2,31 €
PSPE22-60-14	22	17	14	60	58	20	-	2,25 €

*Depending on availability - Dimensions in mm

Flexible tube handle

For tubes Ø12 to Ø22

PSPD18

Knurled cylindrical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly


- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

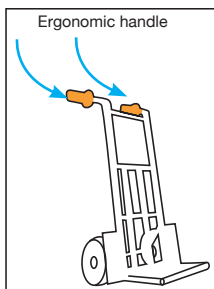

Typical application

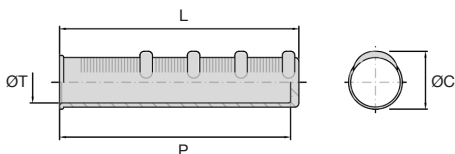

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	L	ØT	ØC	P	Weight (g)	Stock*	Price each 1 to 59
PSPD18-118-12	118	12	28	113	52	-	4,14 €
PSPD18-118-14	118	14	28	113	45	-	3,84 €
PSPD18-118-16	118	16	28	113	40	-	3,54 €
PSPD18-118-18	118	18	28	113	35	-	3,18 €
PSPD18-118-20	118	20	28	113	28	-	2,43 €
PSPD18-118-21	118	21	28	113	26	-	2,25 €
PSPD18-118-22	118	22	28	113	22	-	2,07 €
PSPD18-118-22L	118	22	28	113	19	-	2,13 €

*Depending on availability - Dimensions in mm

Flexible tube handle

PSPD40

For tubes Ø18 and Ø22

Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:
Black PVC

Assembly

- Fit using a mallet, no adhesive required

Advantages

- Ergonomic handle for excellent grip

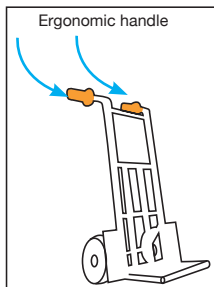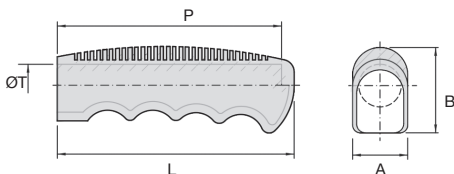

Typical application

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request


Part number	L	A	B	ØT	P	Weight (g)	Stock*	Price each 1 to 59
PSPD40-112-18	112	26	40	18	106	49	-	4,59 €
PSPD40-112-22	112	26	40	22	106	47	-	4,59 €

*Depending on availability - Dimensions in mm

Altri prodotti...



PTMR
Telescopic furniture
foot, threaded stud

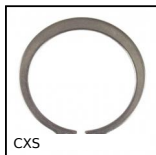

CXS
Anello di arresto
esterno DIN471,
esterno DIN 471



DOMI50
Slitta di regolazione
Domino 50, Slitta
DOMILINE 50 con
contatore e ...



CHML50
Riduttore a ruota e
vite senza fine, fino a
107 Nm - Con
limitatore ...



PTA150
Piede snodato con
base stampata Ø150,
Ø 150



NSR
Connettore rinvio
d'angolo, Regolabile



PGT
Accessori per
pannello, Profilo per
pannello scorrevole



DBL880
Rotella per catena,
Serie 880 e 881



MCL
Manicotto cilindrico
maschiato, Cilindrico -
acciaio



HTD8M_30
Puleggia dentata di
trasmissione tipo
HTD, HTD8 Acciaio



CHAE6555
Cerniera ad avvitare
estetica, Alluminio



RPCtc
Ruota girevole a foro
centrale, Acciaio -
Poliammide - a doppio
bloc...

Prodotti correlati



PSPD18
Manopola a pressione,
PVC nero



PSPT
Manopola a pressione,
PVC



PSPD40
Manopola a pressione,
PVC nero



PSPE20
Conical flexible shaft
handle Ø20, Black
PVC