

Drive sprocket for plate chain


PT820 For chain ranges 820 and 815

- For driving CAP820 and CAP815 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages



Advantage

- Two part design facilitates easy assembly

Easy assembly

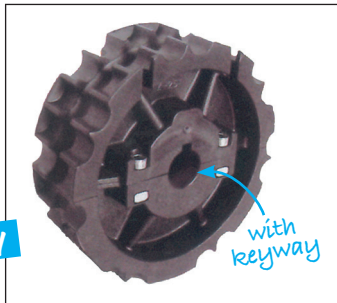

Two part design

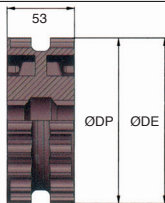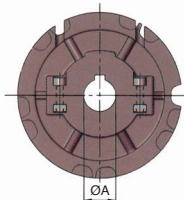


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT820-21-25	21	129	129,26	25	0,4	28,49 €
PT820-21-30	21	129	129,26	30	0,4	28,49 €
PT820-21-35	21	129	129,26	35	0,4	28,49 €
PT820-21-40	21	129	129,26	40	0,4	28,49 €
PT820-21-45	21	129	129,26	45	0,4	28,49 €
PT820-23-25	23	141	141,22	25	0,5	30,09 €
PT820-23-30	23	141	141,22	30	0,5	30,09 €
PT820-23-35	23	141	141,22	35	0,5	30,09 €
PT820-23-40	23	141	141,22	40	0,5	30,09 €
PT820-23-45	23	141	141,22	45	0,5	30,09 €
PT820-25-25	25	153	153,20	25	0,5	30,39 €
PT820-25-30	25	153	153,20	30	0,5	30,39 €
PT820-25-35	25	153	153,20	35	0,5	30,39 €
PT820-25-40	25	153	153,20	40	0,5	30,39 €
PT820-25-45	25	153	153,20	45	0,5	30,39 €

Dimensions in mm

Altri prodotti...

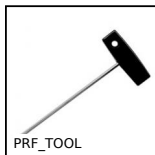

PRF_TOOL
Attrezzi, Chiave di montaggio



ZBRA
Ingranaggio conico in plastica, 1:1



ACL-APB
Sistema di chiusura, Fermporta magnetico



ASM
Cuscinetto cilindrico, Polimero alimentare



PCM
Impugnatura cilindrica fissa, Impugnatura non girevole



BPL
Sfera portante con flangia, Leggero



CHT
Motore AC asincrono trifase, 0.09kW



PSG3
Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato



PTA100ssEB
Piede snodato con base stampata Ø100, Piede snodato



PSG255
Ingranaggio dritto di precisione, Inox 303



PRF-SCL
Sistema di chiusura per profili alluminio, Lock for sliding doors



INSTool
Boccola autofilettante - Attrezzo, Strumento di posa

Prodotti correlati



CAP820
Catena a tapparella dritta, Stretta serie 820



CAP815
Catena a tapparella dritta, Stretta serie 815



DBL820
Rotella per catena, Serie 820 e 815



BAP25
Anello di bloccaggio, Ø25 - Ø40