



# Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly

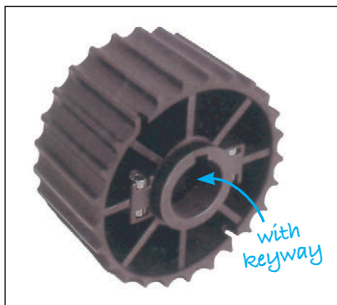

Two part design

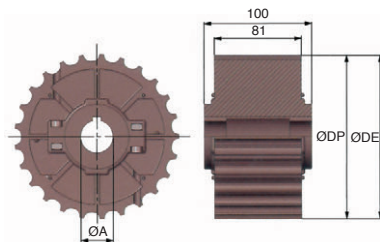


## DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Altri prodotti...

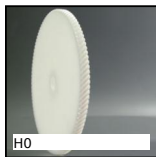

H0  
Ingranaggio elicoidale  
ad assi incrociati a  
90°, Plastica lavorata  
...



RFVcap  
Coperchio di  
protezione inox,  
Coperchio di  
protezione aperto



RLX  
Rullo folle plastica,  
PVC



ACM\_AZ  
Aggancio per tirante  
chiusura in gomma,  
Aggancio



PMC150\_M16  
Supporto antivibrante  
a campana, Piastra a  
base quadrata



PRT  
Corona girevole  
Iglidur®, Iglidur®,  
alluminio e inox



BABss  
Perno autobloccante  
inox 303, Inox 303



RBGpl  
Ruota girevole a  
doppio bloccaggio,  
Acciaio - gomma  
grigia




PSG1  
Ingranaggio dritto di  
precisione, Acciaio  
20NCD2 cementato  
temprato



EKN  
Giunto a soffietto  
Gerwah®, da 0.5 a  
12Nm



VLBG  
Anello di  
sollevamento,  
Girevole

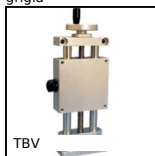

TBV  
Tavola di  
posizionamento  
verticale manuale,  
12kg

## Prodotti correlati



CAP821  
Catena a tapparella  
dritta, Larga serie 821



CAP805  
Catena a tapparella  
dritta, Larga serie 805