



# Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


## Advantage

- Two part design facilitates easy assembly

Easy assembly

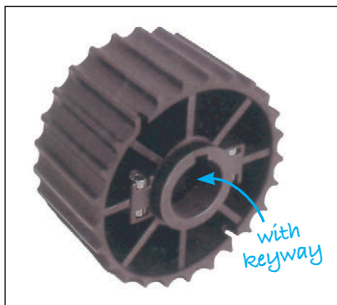

Two part design

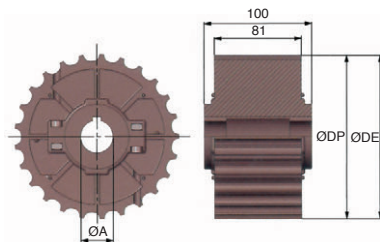

## DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

## Altri prodotti...



RNAS  
Rotelle, Senza anello interno



PENC  
Maniglia da incasso, montaggio a scatto



BSPM  
Vite a ricircolo di sfere miniatura, Dado + vite a ricircolo di sfere



SH2  
Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



ACL  
Angolare, Angolare orientabile



BAP  
Anello di bloccaggio, Ø10 - Ø20



SH0  
Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



CTss  
Giunto cardanico telescopico inox, Sollecitazioni leggere



TBD  
Tavola di posizionamento a



TM\_CTM\_CTF  
Accessori per ventosa, Inserto per ventosa -



BH01  
Cuscinetto radiale flangiato, Montaggio :



UGH50  
Unità di guida tipo H, Per martinetti Ø 50

## Prodotti correlati



CAP821  
Catena a tapparella dritta, Larga serie 821



CAP805  
Catena a tapparella dritta, Larga serie 805