



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

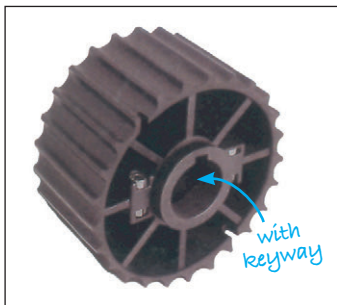

Two part design

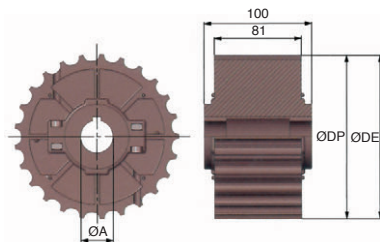

DISCOUNTS

| | | | |
|------------|-----|------------|-----|
| Qty. | 1+ | 5+ | 10+ |
| Disc. List | -5% | On request | |

| Part number | No. of teeth | ØDE | ØDP | Bore ØA | Weight (kg) | Price each 1 to 4 |
|-------------|--------------|-----|-------|---------|-------------|-------------------|
| PT821-25-30 | 25 | 153 | 153,2 | 30 | 0,9 | 70,12 € |
| PT821-25-35 | 25 | 153 | 153,2 | 35 | 0,9 | 70,12 € |
| PT821-25-40 | 25 | 153 | 153,2 | 40 | 0,9 | 70,12 € |
| PT821-25-45 | 25 | 153 | 153,2 | 45 | 0,9 | 70,12 € |

Dimensions in mm

Altri prodotti...



NSA
Connettore rinvio d'angolo, Articolato



MEFC
Cuscinetto a collare, Lega di ferro FP20 autolubrificante METAFRAM



HTD5M_15
Puleggia dentata di trasmissione tipo HTD, HTD5 Acciaio



TBD
Tavola di posizionamento a passo inverso manuale, 40kg



DOG111
Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm



J53
Riduttore coassiale a treni paralleli, da 0.27 a 0.90 - a treni para...



CHINV
Cerniera invisibile, Invisibile - Apertura 90°



PPD
Pistoncino a molla, Per lamiera



LRM
Dado cilindrico in bronzo, Bronzo - 1



UGH32
Unità di guida tipo H, Per martinetti Ø 32



CHB
Feet, For CHB gearbox



BFA
Anelli d'arresto per alberi, Anello tipo E

Prodotti correlati



CAP821
Catena a tapparella dritta, Larga serie 821



CAP805
Catena a tapparella dritta, Larga serie 805