



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

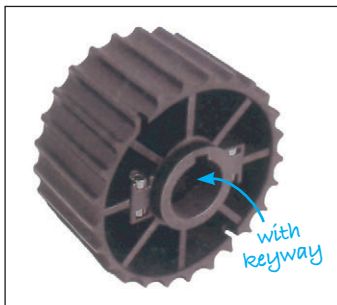

Two part design

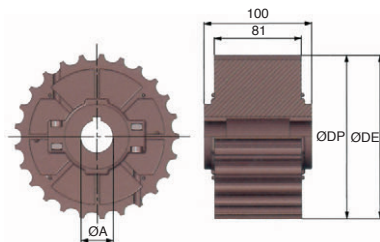

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



PRF_BR
Elementi di giunzione,
Flangia per profilato



NPTF30
Morsetto di
collegamento,
Distanziale Ø14 a Ø20



HLA19
Rinvio angolare a
dentatura spiroidale,
Fino a 43Nm



BG
Giunto Oldham, con
vite a pressione



SCR
Accessori per ventosa,
Adattatore per inserto



PFM
Piede senza snodo,
Lamiera modellata




MDB_MTB
Ingranaggio conico in
plastica stampata, 2:1



DB
Ingranaggio conico -
Acciaio 60C40, 2:1



BAG0
Anello di bloccaggio,
Inox

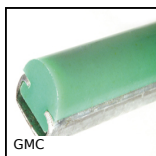

GMC
Guida prodotto
laterale tonda, Per
imbottigliamento e



T5P_T10P
Piastra di giunzione
per cinghia T, T10



PR125
Piede fissabile con
snodo - poliammide, Ø
123

Prodotti correlati



CAP821
Catena a tapparella
dritta, Larga serie 821



CAP805
Catena a tapparella
dritta, Larga serie 805