



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

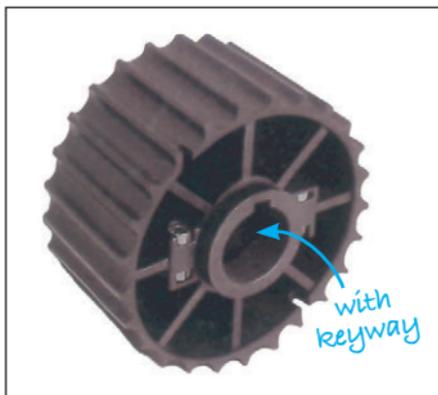

Two part design

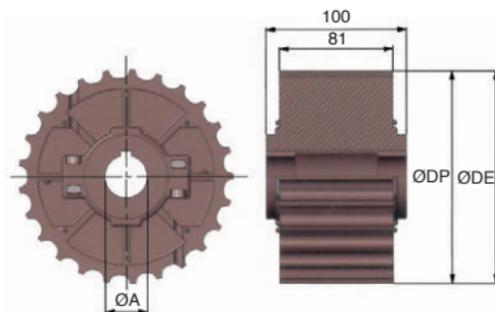

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



G-ECO15

Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



IN0

Ingranaggio interno,
Acciaio 20NCD2



BAN

Connettore / supporto
per profili alluminio,
Regolabile



Q1

Cuscinetto orientabile
a sfere, Acciaio



SBF

Sealed flange bearing
unit for Food Industry,
cover



GMC

Guida prodotto
laterale tonda, Per
imbottigliamento e
imballaggio



P20

Riduttore a ruota e
vite senza fine, fino a
5 Nm



VAP

Magnete con foro
centrale, Con foro
centrale



HW_HT

Guida su semi-binari,
Binario



SVT5

Martinetto a vite - Vite
traslante, Vite



SSB

Ingranaggio conico
inox, 1:1



STRIP

Spazzola strip,
Lunghezza 3m

Prodotti correlati



CAP821

Catena a tapparella
dritta, Larga serie 821



CAP805

Catena a tapparella
dritta, Larga serie 805