



Drive sprocket for plate chain

For chain ranges 821 and 805


PT821

- For driving CAP821 and CAP805 plate chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly

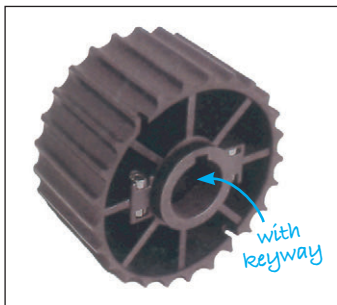

Two part design

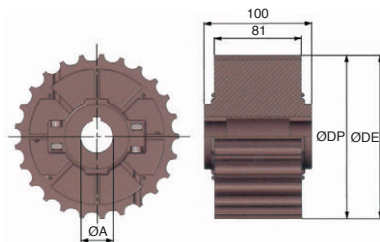

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT821-25-30	25	153	153,2	30	0,9	70,12 €
PT821-25-35	25	153	153,2	35	0,9	70,12 €
PT821-25-40	25	153	153,2	40	0,9	70,12 €
PT821-25-45	25	153	153,2	45	0,9	70,12 €

Dimensions in mm

Altri prodotti...



CHA38_SS
Cerniera su facciata
ad avvitare inox, Su
facciata



SLB
Pistoncino a molla,
acciaio classe 5.8



MFBC
Giunto a soffietto,
Alluminio e bronzo -
con ganascia di
serraggio



SH0
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



BPH
Sfera portante a
incastro cilindrico,
Forte



M1
Coppia ruota e vite
senza fine, Bronzo



RVM25
Riduttore manuale,
Rinvio angolare



GAL 42
Rullo per
trasportatore, Senza
cuscinetti a sfere



PTRSS
Pignone tendicatena,
Per ambienti
Forte



LVT
Mini martinetto
motorizzato 1A, 1



MHX
Manicotto esagonale
maschiato, Esagonale



PSG25
Ingranaggio dritto di
precisione, Inox 303

Prodotti correlati



CAP821
Catena a tapparella
dritta, Larga serie 821



CAP805
Catena a tapparella
dritta, Larga serie 805