

# Drive sprocket for plate chain

## PT882

## For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**



Two part design

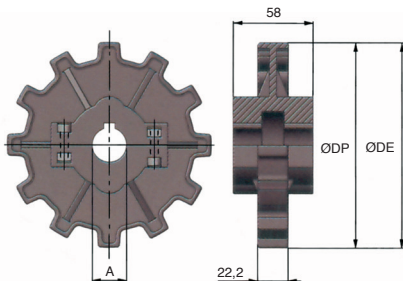

### DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Altri prodotti...




CHAE6555

Cerniera ad avvitare estetica, Alluminio



RPCtcss

Ruota girevole a foro centrale, Inox - Poliammide

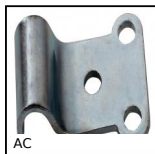

AC

Piastrina di riscontro, 15mm



SSG1\_304L

Ingranaggio dritto, Inox, Inox 304L



GLB

Volantino a 6 lobi, Tecnopolimero - Ottone



BCAss

Boccola scanalata, Inox, Inox




PF45

Riduttore a ruota e vite senza fine, fino a 40 Nm



SH0

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)

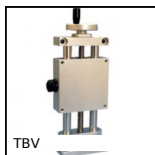

TBV

Tavola di posizionamento




RFV40

Riduttore inox a ruota e vite senza fine, fino a 40 Nm



CLR

Staffa di montaggio per molla a gas,

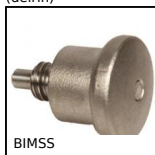

BIMSS

Pistoncino a molla, Miniatura inox

**Prodotti correlati**