

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

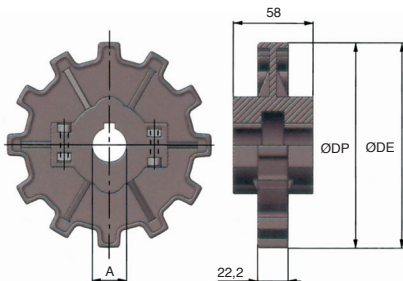

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



LQT

Chiusura a sfera,
Chiusura rapida



CMAss

Vite ad occhiello, Inox



SLHVlok

Bloccaggio a leva, A
leva orizzontale / base
verticale



PM3

Coppia ruota e vite
senza fine, Acciaio
temprato



CHM63-MOT

Motoriduttore AC
asincrono 0,37 a
1,5kW, 0.37 a 1.5kW



GE_ES

Snodo sferico,
acciaio/acciaio



T5M_T10M

Cinghia aperta al
metro tipo T, T10
Poliuretano armatura
in acciaio



LWL

Guida lineare a sfere -
Sfere inox, Binario -
da 514 N a 16700 N



SEH

Attrezzo di bloccaggio
a tirante, A tirante -



ALIDRP240

Alimentazione, 10 A



DCG

Ventosa, Gomma
naturale



HBM

Guida su semi-binari,
Boccola di regolazione

Prodotti correlati