

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

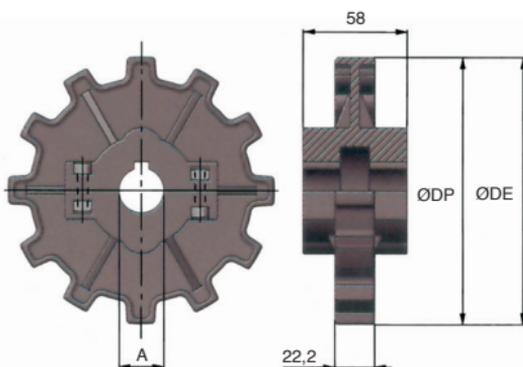

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



GFX

Giunto a dentatura bombata serie economica, Acciaio e poliammide



NPTF20

Morsetto di collegamento, Fisso Ø10 a Ø14



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



MPB

Distanziatore esagonale, Ottone



HTD8M-BAR

Barra dentata per cinghia RPP, HTD8



ACLERP

Rulliera, Con guida laterale



Q7

Cuscinetto obliquo a sfere, Acciaio




BAGtr

Anello di tenuta per vite trapezoidale, Alluminio



PSG25

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato

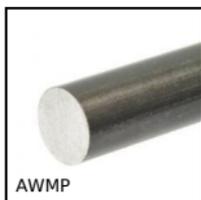

AWMP

Albero in alluminio per guida lineare, Alluminio



PGM52-M4

Maniglia a ponte, Alluminio



VELM4

Supporto avvitabile per rotolo a strappo fermacavi, Poliammide

Prodotti correlati