

Drive sprocket for plate chain

PT882

For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
 - Reinforced polyamide
 - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


Advantage

- Two part design facilitates easy assembly

Easy assembly



Two part design

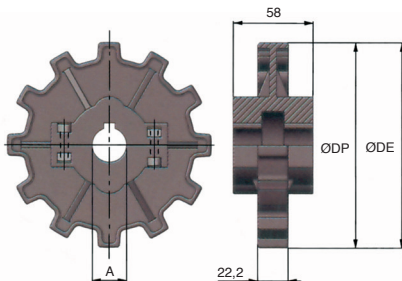

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

Altri prodotti...



HTD3M_09

Puleggia dentata di trasmissione tipo HTD, HTD3 Alluminio



PMC150_M16

Supporto antivibrante a campana, Piastra a base quadrata



RJA00_28

Guarnizione in gomma, Da agganciare



AT10-32ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT10 a...



RPCtcss

Ruota girevole a foro centrale, Inox - Poliammide



E60

Riduttore a rinvio angolare, da 4.50 a 62 Nm



BWU

Guida lineare di precisione, da 1510 N a 10500 N



CHTRB

Riduttore a rinvio angolare a L o a T, fino a 4,7 Nm



PAT123

Piede snodato con base lamiera Ø123, Ø




AZY

Antivibrante elastico cilindrico, Acciaio



VHTM

Hexagonal headed bolt Hygienic

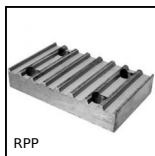

RPP

Piastra di giunzione per cinghia RPP, RPP8

Prodotti correlati