

# Drive sprocket for plate chain

## PT882

## For chain range 882 TAB

- For driving CAP882T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**



Two part design

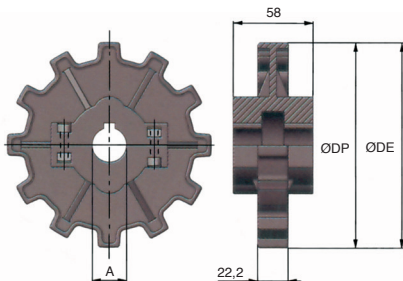

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT882-12-25	12	148,5	147,2	25	0,38	29,36 €
PT882-12-30	12	148,5	147,2	30	0,38	29,36 €
PT882-12-35	12	148,5	147,2	35	0,38	29,36 €
PT882-12-40	12	148,5	147,2	40	0,38	29,36 €
PT882-12-45	12	148,5	147,2	45	0,38	29,36 €

Dimensions in mm

## Altri prodotti...




HBM  
Guida su semi-binari,  
Boccola di regolazione



PTAF80-PAMF80  
Piede fissabile con  
base lamiera Ø80, Ø  
80



DEP  
Attrezzi Hygienic  
Usit® and Hygienic  
Design®, Bussole per  
il monta...

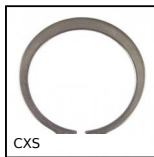

CX5  
Anello di arresto  
esterno DIN471,  
esterno DIN 471



VPSS  
Volantino a 6 lobi,  
Duroplast - Inox



NAST  
Rotelle. Con anello  
interno



EX  
Albero per riduttori E,  
Albero semplice per  
riduttori E



PTR  
Pignone tendicatena,  
Per applicazioni  
correnti



DPAK\_DKON  
Piedino antivibrante  
parabolico, Acciaio



RTK  
Giunto Bowex®, a  
dentatura bombata,  
Nylon e acciaio



SCE  
Serracavo, Acciaio



PSG15  
Ingranaggio dritto di  
precisione, Acciaio  
35NCD6 pretrattato

**Prodotti correlati**