

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

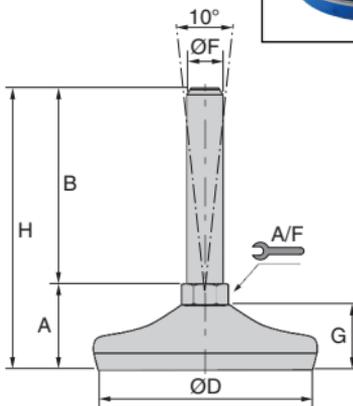

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15€/min + prix appel

Our other products



NDS20
Double cross clamp,
Parallel



SEV
Clamp, Vertical Latch
Clamp - steel



PRES
Accessories for
PRES-3HR and
PRES-4HR presses,
Tool holder



NSU
Sensor support,
Universal 90° support
clamp



V3RA_PT
Hand wheel,
Polyamide



P55
Worm and wheel
gearbox, up to 57 Nm



RAM30
Manual gearbox,
Bevel



DBL805
Idler, Range 805




MEB
Moulded plastic bevel
gear (nylon), 1:1



PRF_BM
Floor anchor, Central
base fixation



ECF
Well nut, Elastomer

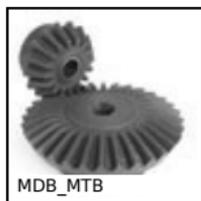

MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base,
Articulated foot




PAMF80EB
Articulated foot with
sheet metal base,
Articulated foot



PAMF100EB
Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...

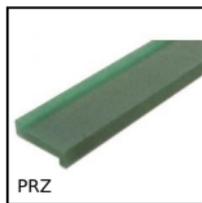

PRZ

Profilo supporto per catena, Profilo a Z ad incastro



PR125

Piede fissabile con snodo - poliammide, Ø 123



IN1

Ingranaggio interno, Acciaio 20NCD2



S_2RS

Cuscinetto radiale a sfere, Inox



EHD08-9

Riduttore coassiale, da 35 a 50 Nm



P60

Riduttore a ruota e vite senza fine, fino a 118 Nm



BTE

Tenditore automatico universale, Per applicazioni correnti




PITAss

Pistoncino a molla, con maniglia a T



ACLBTS

Sistema di chiusura per profili alluminio,

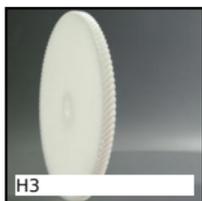

H3

Ingranaggio elicoidale ad assi incrociati a



AT5P_AT10P

Piastra di giunzione per cinghia AT, AT10



RAG

Guida di scorrimento a rullini,

Prodotti correlati



PTA50ssEB

Piede snodato con base stampata Ø50, 4000N



PTA80ssEB

Piede snodato con base stampata Ø80, 10000N



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato