

# Articulated foot with sheet metal base Ø100

## PTA100SS/EB

Max load: 15,000N  
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

### Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

### Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

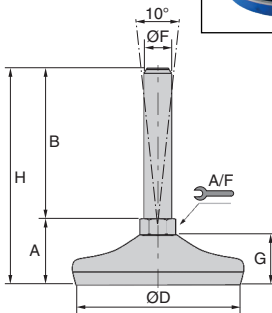

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request


Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

\* Depending on availability - Dimensions in mm

## Our other products



NDS20  
Double cross clamp,  
Parallel

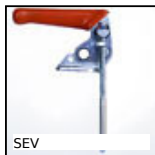

SEV  
Clamp, Vertical Latch  
Clamp - steel



PRES  
Accessories for  
PRES-3HR and  
PRES-4HR presses,  
Tool holder



NSU  
Sensor support,  
Universal 90° support  
clamp



V3RA\_PT  
Hand wheel,  
Polyamide



P55  
Worm and wheel  
gearbox, up to 57 Nm



RAM30  
Manual gearbox,  
Bevel



DBL805  
Idler, Range 805



MEB  
Moulded plastic bevel  
gear (nylon), 1:1



PRF\_BM  
Floor anchor, Central  
base fixation



ECF  
Well nut, Elastomer



MDB\_MTB  
Moulded plastic bevel  
gear (nylon), 2:1

## Complementary products



PTA50ssEB  
Articulated foot with  
sheet metal base,  
Articulated foot



PTA80ssEB  
Articulated foot with  
sheet metal base,  
Articulated foot



PAMF80EB  
Articulated foot with  
sheet metal base,  
Articulated foot



PAMF100EB  
Articulated foot with  
sheet metal base,  
Articulated foot

## Altri prodotti...



VRC2  
Staffa di bloccaggio 2  
lati, 2 lati




PRF\_PL\_9090  
Elementi di giunzione,  
Piastra di fissaggio -  
90x90 mm



M1  
Coppia ruota e vite  
senza fine, Bronzo



BLHT40  
Rinvio angolare a T,  
da 4 a 10.30 Nm

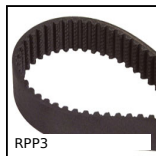

RPP3  
Cinghia di  
trasmissione RPP,  
RPP3



SH2  
Ingranaggio elicoidale  
ad assi paralleli,  
Plastica lavorata  
(delrin)



BH02  
Cuscinetto radiale  
flangiato, Montaggio  
con circlips



FB\_ECO  
Ingranaggio conico -  
Acciaio C43 - ECO, 4:1



PSG1  
Ingranaggio dritto di  
precisione, Acciaio  
35NCD6 pretrattato



M1  
Coppia ruota e vite  
senza fine , Acciaio  
non temprato



PGT  
Accessori per  
pannello, Profilo per  
pannello scorrevole



RT70  
Calettatore di  
bloccaggio, Coppia  
media/elevata

## Prodotti correlati



PTA50ssEB  
Piede snodato con  
base stampata Ø50,  
Piede snodato



PTA80ssEB  
Piede snodato con  
base stampata Ø80,  
Piede snodato



PAMF80EB  
Piede snodato con  
base stampata  
fissabile Ø80, Piede  
snodato



PAMF100EB  
Piede snodato con  
base stampata  
fissabile Ø100, Piede  
snodato