

SteSta Pressed steel articulated foot Ø150

Accepts loads up to 40,000N

PTA150
PTA150ss

- **Levelling foot**
- Brilliant finish (Sand-blasted finish for base of the stainless steel version)
- Materials:


Steel version:

Base: Chromed steel sheet C40
Rod: Chromed steel (nut not supplied)
Sole: Vulcanised rubber NBR hardness 80° Shore

Stainless steel version:

Base: 304 stainless steel, brilliant or sand-blasted finish
Rod: 304 stainless steel (nut not supplied)
Sole: Vulcanised rubber NBR hardness 80° Shore

Sand-blasted stainless-steel version

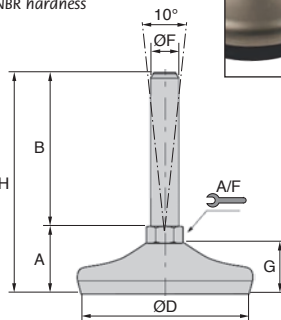

Options

- Other rod sizes are available

DISCOUNTS

Qty	1+	15+	20+	25+	40+
Disc.	List -5%	-10%	-15%		On request

Part number		ØD	ØF	B	A	A/F	G	H	Static load (N)	Price each 1 to 14
bright	sanded finish									
Steel foot										
PTA150-24-100	-	150	M24	100	44	24	35	144	40000	52.69 €
PTA150-24-150	-	150	M24	150	44	24	35	194	40000	55.61 €
PTA150-24-200	-	150	M24	200	44	24	35	244	40000	58.77 €
PTA150-24-250	-	150	M24	250	44	24	35	294	40000	61.72 €
PTA150-30-100	-	150	M30	100	44	30	35	145	40000	57.84 €
PTA150-30-150	-	150	M30	150	44	30	35	195	40000	59.65 €
PTA150-30-200	-	150	M30	200	44	30	35	245	40000	65.66 €
PTA150-30-250	-	150	M30	250	44	30	35	295	40000	73.95 €
Stainless steel foot										
PTA150-24-100/SS	PTA150-24-100/SS/SB	150	M24	100	49	20	35	149	40000	72.32 €
PTA150-24-150/SS	PTA150-24-150/SS/SB	150	M24	150	49	20	35	199	40000	76.29 €
PTA150-24-200/SS	PTA150-24-200/SS/SB	150	M24	200	49	20	35	249	40000	80.27 €
PTA150-24-250/SS	PTA150-24-250/SS/SB	150	M24	250	49	20	35	299	40000	84.26 €
PTA150-30-100/SS	PTA150-30-100/SS/SB	150	M30	100	50	26	35	150	40000	82.29 €
PTA150-30-150/SS	PTA150-30-150/SS/SB	150	M30	150	50	26	35	200	40000	88.11 €
PTA150-30-200/SS	PTA150-30-200/SS/SB	150	M30	200	50	26	35	250	40000	93.00 €
PTA150-30-250/SS	PTA150-30-250/SS/SB	150	M30	250	50	26	35	300	40000	97.86 €

All dimensions in mm

0 825 88 6000
Service 0,15 €/min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

Altri prodotti...




SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



SSG0

Ingranaggio dritto Inox, Inox 304L

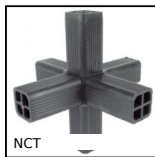

NCT

Giunto di collegamento, Ad angolo fisso



LRR22

Small dimension latch with locking system, Aluminium



HW_HT

Guida su semi-binari, Binario




DOMI120

Slitta di regolazione Domino 120, Slitta DOMILINE 120 con contatore ...



CHAM5270SS

Cerniera ad avvitare in inox, Marine

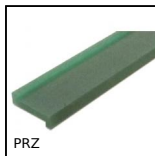

PRZ

Profilo supporto per catena, Profilo a Z da posare



PAP

Maniglia e battuta per porta, Maniglia ergonomica



PR821

Ruota di rinvio, Serie 821 e 805



CLG3

Ingranaggio dritto in plastica stampata , Nylon stampato



F7-P-AM

Visualizzatore multifunzione, Anello magnetico

Prodotti correlati



PTA150

Piede snodato con base stampata Ø150, Ø 150



PTA150

Piede snodato con base stampata Ø150, Ø 150