



Articulated foot with sheet metal base Ø40

Max load: 4000N
Rubber sole in EPDM, blue

PTA40SS/EB

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

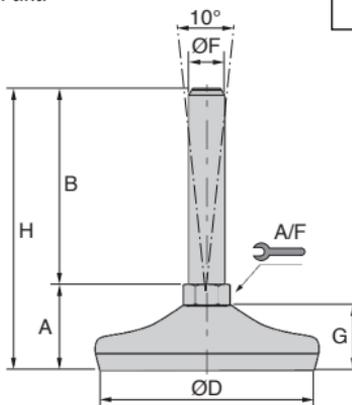

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-15%	-15%	On request

Part number	ØD	ØF	B	A	A/F	G	H	Static load (N)	Stock*	Price per unit 1 to 5
PTA40-8-25/SS/EB	40	M8	25	26	6	15	51	3000	-	13,14 €
PTA40-8-50/SS/EB	40	M8	50	26	6	15	76	3000	-	13,53 €
PTA40-8-75/SS/EB	40	M8	75	26	6	15	101	3000	-	14,01 €
PTA40-10-25/SS/EB	40	M10	25	26	8	15	51	3000	-	14,31 €
PTA40-10-50/SS/EB	40	M10	50	26	8	15	76	3000	-	14,76 €
PTA40-10-75/SS/EB	40	M10	75	26	8	15	101	3000	-	15,21 €
PTA40-10-100/SS/EB	40	M10	100	26	8	15	126	3000	-	16,08 €
PTA40-10-125/SS/EB	40	M10	125	26	8	15	151	3000	-	16,71 €

* Depending on availability - Dimensions in mm

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Food industry

Sole in EPDM, blue




Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

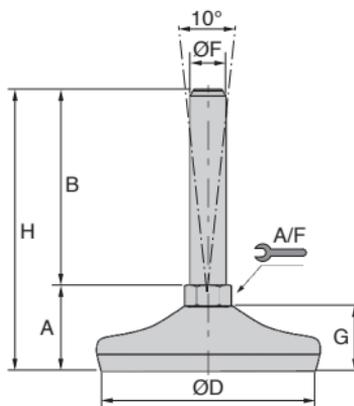

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	18,61 €
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	21,00 €
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	18,61 €
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	21,00 €
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	21,58 €
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	22,40 €
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	24,51 €

* Depending on availability - Dimensions in mm



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

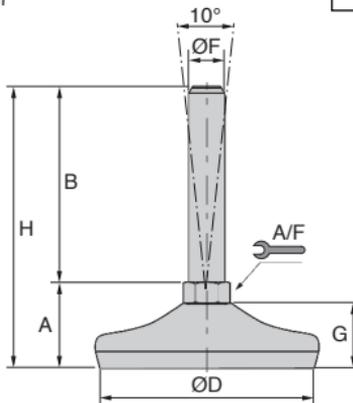

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	31,38 €
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	33,65 €
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	33,65 €
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	35,85 €
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	37,57 €
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	40,32 €
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	44,54 €

* Depending on availability - Dimensions in mm

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

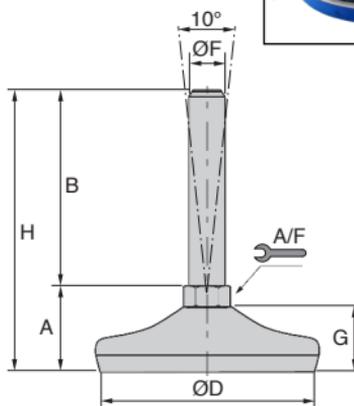

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	48,36 €
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	50,09 €
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	54,00 €
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	51,73 €
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	55,07 €
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	59,00 €
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	55,66 €
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	57,35 €

* Depending on availability - Dimensions in mm



Articulated foot with sheet metal base Ø80

Max load: 10,000N

PAMF80EB

Rubber sole in EPDM, blue

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages


- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment



Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

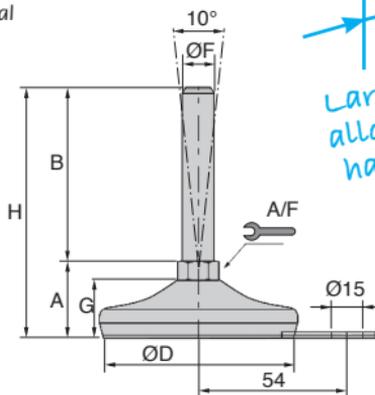

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	38,93 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	41,14 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	39,46 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	42,27 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	45,06 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	45,06 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	47,85 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	52,03 €

*Within the limits of available stock - Dimensions in mm

Articulated foot with sheet metal base Ø100

PAMF100EB

Max load: 15,000N
Rubber sole in EPDM, blue

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:

Base: shiny 304 stainless steel sheet
Thread: 304 stainless steel, supplied without nut
Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

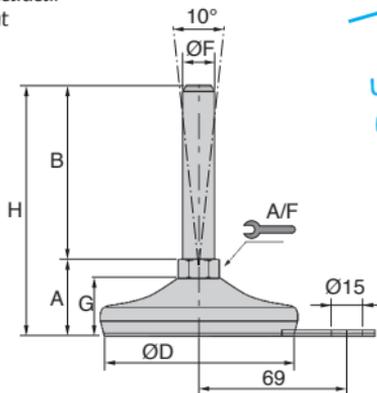

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-15%	On request	

Part N°	Threading							Static load(N)	Price per unit 1 to 5
	ØD	ØF	B	A	A/F	G	H		
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	56,53 €
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	58,24 €
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	62,18 €
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	59,90 €
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	63,32 €
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	67,23 €

* Depending on availability - Dimensions in mm

Altri prodotti...



PAMF100EB
Piede snodato con base stampata fissabile Ø100, Piede snodato



DOMI_MD
Tavola rotante di regolazione Domino, 55/1



LRRss
Interblocco di sicurezza, Chiusura a molla - inox



M0
Coppia ruota e vite senza fine, Acciaio non temprato



CHML40
Riduttore a ruota e vite senza fine, fino a 57 Nm - Con limitatore d...



VRM
Anello di sollevamento, Orientabile femmina



J51
Riduttore coassiale a treni paralleli, da 0.13 a 0.49 - a treni para...



RFV63
Riduttore inox a ruota e vite senza fine, fino a 152 Nm



BSCm
Manopola, Con coppia regolabile



LVT
Mini martinetto motorizzato 4A, 4



S_2RS
Cuscinetto radiale a sfere, Inox



MAC
Moschettone DIN5299 acciaio, Acciaio

Prodotti correlati



PTA50ssEB
Piede snodato con base stampata Ø50, 4000N



PTA80ssEB
Piede snodato con base stampata Ø80, 10000N



PTA100ssEB
Piede snodato con base stampata Ø100, 15000N



PAMF80EB
Piede snodato con base stampata fissabile Ø80, Piede snodato