

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Food industry

Sole in EPDM, blue




Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

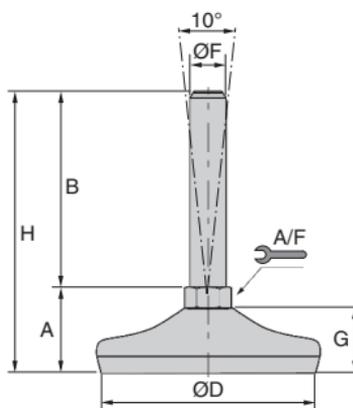

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request


References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

* Depending on availability - Dimensions in mm


Our other products



RTN
Bowex ®, toothed,
Nylon

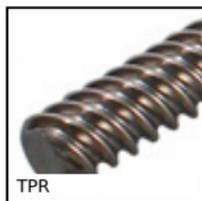

TPR
High helix leadscrew,
Leadscrew only - up
to 40mm per rotation

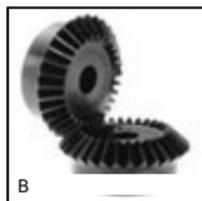

B
Bevel gear - Steel
60C40, 1:1



BPM_LOK
Slotted spring plunger
with ball tip, LONG-
LOK - Steel



BRI
Panels accessories,
Panel holder



PWDL_PWGDL2
Worm - precision
range, Delrin



PBG
Bevel gear - precision
range, 1:1



HTD8M_20
HTD-type pulley for
RPP-type belt, HTD8
Cast



CHT90
3 phase AC
asynchronous motor,
1.1 to 1.85kW



BABss
Ball pin, 303 Stainless
steel



BLHB20
Right angled gearbox,
up to 1.77 Nm



PTKss
Foot for the food
industry, Stainless
steel - 3-A standard

Complementary products



PTA80ssEB
Articulated foot with
sheet metal base,
Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB
Articulated foot with
sheet metal base,
Articulated foot



PAMF100EB
Articulated foot with
sheet metal base,
Articulated foot

Altri prodotti...



PAT123

Piede snodato con base lamiera Ø123, Ø 123



BOX-TOR-C

Valigetta di guarnizioni toriche in nitrile, 3.00 x 1.50mm a 30.20 x...



LRRss

Interblocco di sicurezza, Chiusura a molla - inox



BPLF

Sfera portante alta sporgenza, Leggero



AC

Piastrina di riscontro, 15mm



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg



DIV_SS

Pistoncino a molla, Bloccabile - Inox



DOMI80

Accessori di collegamento, Kit di fissaggio



PTKFss

Piede fissabile speciale agroalimentare, Stainless steel - 3-A



BSM

Pressore a molla con esagone incassato, corpo in acciaio, spina in...



PP50

Riduttore a ruota e vite senza fine, da 6.50 a 12.80 Nm



BPM_LOK

Pressore a molla con intaglio e puntale a sfera, LONG-LOK - Inox 303

Prodotti correlati



PTA80ssEB

Piede snodato con base stampata Ø80, 10000N



PTA100ssEB

Piede snodato con base stampata Ø100, 15000N



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato