

# Articulated foot with sheet metal base Ø50

Max load: 4000N  
Rubber sole in EPDM, blue


- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

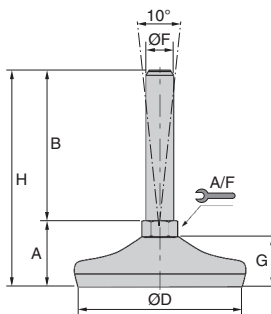

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request


References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA50-10-75/SS/EB	50	M10	75	29	14	19	104	4,000	17,56€
PTA50-10-125/SS/EB	50	M10	125	29	14	19	154	4,000	19,83€
PTA50-12-75/SS/EB	50	M12	75	29	14	19	104	4,000	17,56€
PTA50-12-125/SS/EB	50	M12	125	29	14	19	154	4,000	19,83€
PTA50-16-75/SS/EB	50	M16	75	34	13	19	109	4,000	20,38€
PTA50-16-100/SS/EB	50	M16	100	34	13	19	134	4,000	21,14€
PTA50-16-150/SS/EB	50	M16	150	34	13	19	184	4,000	23,13€

\* Depending on availability - Dimensions in mm


## Our other products



RTN  
Bowex ®, toothed,  
Nylon

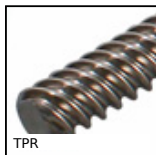

TPR  
High helix leadscrew,  
Leadscrew only - up  
to 40mm per rotation

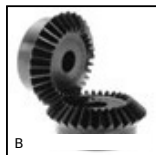

B  
Bevel gear - Steel  
60C40, 1:1



BPM\_LOK  
Slotted spring plunger  
with ball tip, LONG-  
LOK - Steel



BRI  
Panels accessories,  
Panel holder



PWDL\_PWGDL2  
Worm - precision  
range, Delrin



PBG  
Bevel gear - precision  
range, 1:1



HTD8M\_20  
HTD-type pulley for  
RPP-type belt, HTD8  
Cast



CHT90  
3 phase AC  
asynchronous motor,  
1.1 to 1.85kW



BABss  
Ball pin, 303 Stainless  
steel



BLHB20  
Right angled gearbox,  
up to 1.77 Nm



PTKss  
Foot for the food  
industry, Stainless  
steel - 3-A standard

## Complementary products



PTA80ssEB  
Articulated foot with  
sheet metal base,  
Articulated foot



PTA100ssEB  
Articulated foot with  
sheet metal base,  
Articulated foot



PAMF80EB  
Articulated foot with  
sheet metal base,  
Articulated foot



PAMF100EB  
Articulated foot with  
sheet metal base,  
Articulated foot

## Altri prodotti...



UTKpwcr

Guida lineare Utilitrack®, Carrello a rotelle - rivestimento polimero



CLLCLLP

Forcella serie lunga, Lunga acciaio



RPCplss

Ruota girevole a doppio bloccaggio, Inox - poliammide




CHAFR-MINI

Cerniera, A frizione



EMR

Volantino zigrinato a serraggio rapido, Zigrinato

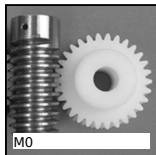

M0

Coppia ruota e vite senza fine , Plastica lavorata (delrin)



CHML50

Riduttore a ruota e vite senza fine, fino a 107 Nm - Con limitatore ...



GP75

Chiusura a leva molla a trazione compensata, Standard (GP75)



BEK

Vite a ricircolo di sfere miniatura, Supporto



MCLred

Manicotto di riduzione, Cilindrico - acciaio



SSDB

Ingranaggio conico inox, 2:1



HG5

Ingranaggio dritto acciaio , Acciaio 20NCD2

## Prodotti correlati



PTA80ssEB

Piede snodato con base stampata Ø80, Piede snodato



PTA100ssEB

Piede snodato con base stampata Ø100, Piede snodato



PAMF80EB

Piede snodato con base stampata fissabile Ø80, Piede snodato



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato