



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**  
Base: shiny 304 stainless steel sheet  
Thread: 304 stainless steel, supplied without nut  
Sole: EPDM blue

## Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

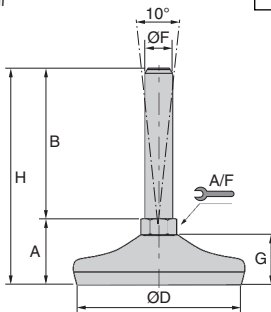

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

\* Depending on availability - Dimensions in mm

## Our other products




BLH20

Right angled gearbox, from 0.53 to 1.77



RCC\_RCX

Spherical tilt washer - DIN 6319, concave

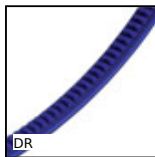

DR

Plastic flexible rack, Rack



DOG319

DC Motor and gearbox combination, from 4 to 9 Nm



E50

Angle transmission gearbox, from 3 to 41 Nm



MEB

Moulded plastic bevel gear (nylon), 1:1



GE1006

Flexible toggle latch, Hooks into a slot



PAMF80EB

Articulated foot with sheet metal base, Articulated foot



INS\_SS

Self tapping insert, Stainless steel



V3RA\_PTR

Hand wheel, Polyamide



SFE

Rod end, Stainless steel / PTFE



RT70

Locking Assembly, Medium/high torque

## Complementary products



PTA50ssEB

Articulated foot with sheet metal base, Articulated foot



PTA100ssEB

Articulated foot with sheet metal base, Articulated foot



PAMF80EB

Articulated foot with sheet metal base, Articulated foot



PAMF100EB

Articulated foot with sheet metal base, Articulated foot

## Altri prodotti...



HW\_HT  
Guida su semi-binari,  
Ruota



G4-ECO  
Ingranaggio dritto  
acciaio - serie ECO,  
Acciaio C45



YG1  
Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6



LRR  
Chiavistello con perno  
prismatico, Lucchetto  
a molla



CHTRP  
Riduttore a rinvio  
angolare a L o a T,  
fino a 9,1 Nm



RHTplss  
Ruota alte  
temperature, fino a  
200kg



GE14  
Chiusura a leva, Con  
porta-lucchetto



MRASeco  
Maglia rapida  
economica, Inox



B3PAN  
Panamech, Multi-  
Beam inox, Inox - con



PHG05  
Ingranaggio elicoidale  
ad assi paralleli,



GE  
Chiusura a leva,  
Miniature



M1  
Coppia ruota e vite  
senza fine, Bronzo

## Prodotti correlati



PTA50ssEB  
Piede snodato con  
base stampata Ø50,  
Piede snodato



PTA100ssEB  
Piede snodato con  
base stampata Ø100,  
Piede snodato



PAMF80EB  
Piede snodato con  
base stampata  
fissabile Ø80, Piede  
snodato



PAMF100EB  
Piede snodato con  
base stampata  
fissabile Ø100, Piede  
snodato